

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0191270012

Status:

Active

Overview:

Solderless Terminals

Description:

Avikrimp Flanged Spade Tongue Terminal for 22-18 AWG Wire, Stud Size 10 (M5)

Documents:

3D Model

3D Model (PDF)

Drawing (PDF)

Product Specification PS-19902-011-001 (PDF)

Product Specification PS-19902-013-001 (PDF)

Packaging Specification PK-19902-001-001 (PDF)

RoHS Certificate of Compliance (PDF)

Agency Certification

CSA

UL

LR18689

E32244

General

Product Family

Series

Crimp Quality Equipment

Overview

Product Name

Taxonomy

Type

UPC

Ring and Spade Terminals

19127

Yes

Solderless Terminals

Avikrimp

Ring and Spade Terminals

Spade

800753098947

Physical

Barrel Type

Flammability

Insulation

Material - Plating Mating

Net Weight

Packaging Type

Stud Size

Wire Insulation Diameter

Wire Size AWG

Wire Size mm²

Closed

94V-2

Nylon (PA)

Tin

0.760/g

Bag

10 (M5)

3.56mm max.

18, 20, 22

0.25-1.50

Material Info

Engineering Number

AA-815-10

Reference - Drawing Numbers

Packaging Specification


Product Specification

Sales Drawing

PK-19902-001-001

PS-19902-011-001, PS-19902-013-001

SD-19127-003-001

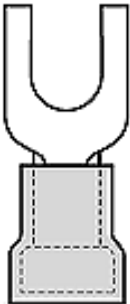

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

China RoHS

Compliant

REACH SVHC

Not Contained Per -

D(2021)4569-DC (8

July 2021)

Halogen-Free

Status

Low-Halogen

For more information, please visit

Contact US

China ROHS

Green Image

ELV

Not Relevant

RoHS Phthalates

Not Contained

Search Parts in this Series

19127 Series

Application Tooling | FAQ

Tooling specifications and manuals are found by selecting the products below. Crimp Height Specifications are then contained in the Application Tooling Specification document.

Global	
Description	Product #
PremiumGrade	640010100
Hand Crimp Tool for Avikrimp and Insulkrimp Terminals and Splices, 10-22 AWG and 6.0-0.5mm² (Rings, Spades, Hooks, Block Spades and Flanged Spades)	
Crimp Head for the AT-200 Pneumatic Hand Tool	640050100

ServiceGrade Hand 640160036
Crimp Tool for Field
Repair only, for
production use our
PremiumGrade Tool

This document was generated on 02/01/2023

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION