

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0022552401

Status:


Active

Overview:

SL Modular Connectors

Description:

2.54mm Pitch SL Crimp Housing, Dual Row, Version A, Non-polarized, 40 Circuits, Black

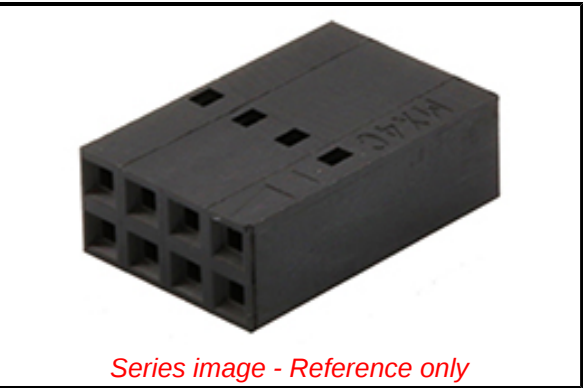

Documents:

3D Model

3D Model (PDF)

Drawing (PDF)

Product Specification PS-70400-001 (PDF)

Test Summary TS-70058-001-001 (PDF)

RoHS Certificate of Compliance (PDF)

Agency Certification	
CSA	LR19980
UL	E29179
General	
Product Family	Crimp Housings
Series	70450
Application	Signal, Wire-to-Board
Comments	Version A
Overview	SL Modular Connectors
Product Name	SL
UPC	800753588813
Physical	
Breakaway	No
Circuits (maximum)	40
Color - Resin	Black
Flammability	94V-0
Gender	Receptacle
Glow-Wire Capable	No
Material - Resin	Polyester
Net Weight	3.360/g
Number of Rows	2
Packaging Type	Bag
Panel Mount	No
Pitch - Mating Interface	2.54mm
Stackable	Yes
Temperature Range - Operating	-40° to +105°C
Solder Process Data	
Lead-freeProcess Capability	N/A
Material Info	
Engineering Number	70450-0019
Reference - Drawing Numbers	
Product Specification	PS-70400-001
Sales Drawing	SD-70450-0001-0026-0
Test Summary	TS-70058-001-001

EU ELV	
Not Relevant	
EU RoHS	China RoHS
Compliant	
REACH SVHC	
Not Contained Per - D(2020)9139-DC (19 Jan 2021)	
Halogen-Free	
Status	
Not Low-Halogen	
For more information, please visit Contact US	
China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

70450 Series

Mates With

2.54mm Pitch C-Grid Header [70229](#) , [70280](#) , [70246](#) , [70247](#)

Use With

[70058](#) , [71851](#)

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION