

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0029110032

Status:


Active

Overview:

Mini-Latch Wire-to-Board / Wire-to-Wire Connector System

Description:

2.50mm Pitch Mini-Latch Wire-to-Wire Plug Housing, Friction Lock, with Mounting Ears, 3 Circuits, Natural

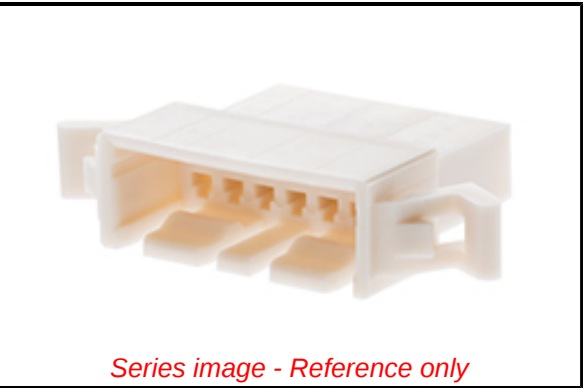

Documents:	
3D Model	Product Specification PS-51191-003-001 (PDF)
3D Model (PDF)	RoHS Certificate of Compliance (PDF)
Drawing (PDF)	

Agency Certification	
CSA	LR19980
UL	E29179
General	
Product Family	Crimp Housings
Series	5240
Application	Signal, Wire-to-Wire
Overview	Mini-Latch Wire-to-Board / Wire-to-Wire Connector System
Product Name	Mini-Latch
Taxonomy	Connector Housings
UPC	800754314459
Physical	
Circuits (maximum)	3
Color - Resin	Natural (White)
Flammability	94V-0
Gender	Plug
Glow-Wire Capable	No
Lock to Mating Part	Yes
Net Weight	843.300/mg
Number of Rows	1
Packaging Type	Bag
Panel Mount	Yes
Pitch - Mating Interface	2.50mm
Stackable	No
Temperature Range - Operating	-40° to +105°C
Material Info	
Engineering Number	5240-03
Reference - Drawing Numbers	
Product Specification	PS-51191-003-001
Sales Drawing	SD-5240-001-001

EU ELV	
Not Relevant	
EU RoHS	China RoHS
Compliant	
REACH SVHC	
Not Contained Per - D(2022)4187-DC (10 June 2022)	
Halogen-Free	
Status	
Low-Halogen	
For more information, please visit Contact US	
China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

5240 Series

Mates With

51191 Housing

Use With

5241

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION