

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0393710003

Status:


Active

Overview:

Eurostyle Terminal Blocks

Description:

7.50mm Beau Eurostyle Pluggable Terminal Block, 180° Wire Entry, 3 Circuits

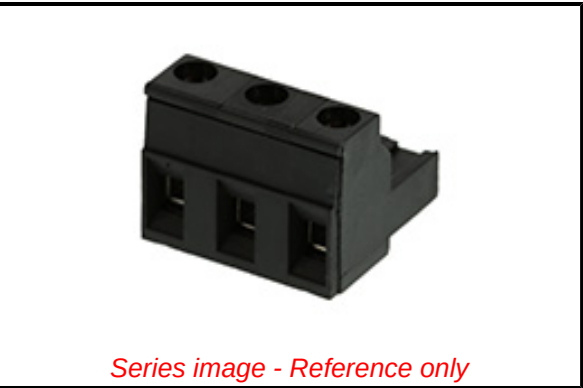

Documents:	
Drawing (PDF)	3D Model
3D Model (PDF)	RoHS Certificate of Compliance (PDF)
Agency Certification	
UL	E48521
General	
Product Family	Terminal Blocks
Series	39371
Application	N/A
Component Type	Plug
Overview	Eurostyle Terminal Blocks
Product Name	Eurostyle Pluggable
Taxonomy	Terminal Blocks and Barrier St
Type	Euro Block
UPC	822348040179
Physical	
Circuits (Loaded)	3
Entry Angle	180° Angle
Flammability	94V-0
Lock to Mating Part	None
Number of Rows	1
Orientation	Right Angle
PCB Retention	N/A
Panel Mount	No
Pitch - Mating Interface	7.50mm
Pitch - Termination Interface	7.50mm
Polarized to Mating Part	Yes
Stackable	Yes
Temperature Range - Operating	110°C
Wire Size AWG	12, 14, 16, 18, 20, 22, 24, 26, 28, 30
Wire Size mm²	0.05-2.50
Electrical	
Current - Maximum per Contact	15.0A
Voltage - Maximum	300V
Material Info	
Engineering Number	MX-CIF03003-0N
Reference - Drawing Numbers	
Sales Drawing	SD-39371-001-001

EU ELV	
Not Relevant	
EU RoHS	China RoHS
Compliant with Exemption 6(c)	
REACH SVHC	
Contained Per - D(2022)4187-DC (10 June 2022)	
Lead	
Halogen-Free	
Status	
Low-Halogen	
For more information, please visit Contact US	
China ROHS	50 Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

[39371](#) Series

Mates With

[39372](#) , [39373](#) Headers

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION