

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0430610006

Status:


Active

Overview:

SPOX Connector System

Description:

3.96mm Pitch SPOX Housing, 6 Circuits, Natural

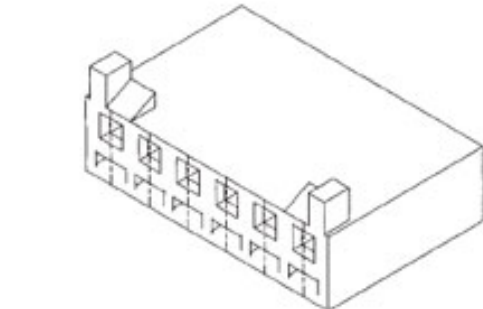

Series image - Reference only

Documents:	
3D Model	Drawing (PDF)
3D Model (PDF)	RoHS Certificate of Compliance (PDF)

Agency Certification	
CSA	LR19980
UL	E29179
General	
Product Family	Crimp Housings
Series	43061
Application	Power, Wire-to-Board
Comments	Glow Wire Equivalent Part Number 430613006
Overview	SPOX Connector System
Product Name	SPOX
UPC	800753629967
Physical	
Breakaway	No
Circuits (maximum)	6
Circuits Detail	6
Color - Resin	Natural
Flammability	94V-0
Gender	Receptacle
Glow-Wire Capable	No
Keying to Mating Part	None
Lock to Mating Part	Yes
Material - Resin	Polyester
Net Weight	1.989/g
Number of Rows	1
Packaging Type	Bag
Panel Mount	No
Pitch - Mating Interface	3.96mm
Pitch - Termination Interface	3.96mm
Polarized to Mating Part	Yes
Stackable	No
Temperature Range - Operating	0° to +75°C
Solder Process Data	
Lead-freeProcess Capability	N/A
Material Info	
Reference - Drawing Numbers	
Sales Drawing	SD-43061-001

EU ELV

Not Relevant

EU RoHS

Compliant

China RoHS

REACH SVHC

Not Contained Per -
D(2020)9139-DC (19
Jan 2021)

Halogen-Free

Status

Not Low-Halogen

For more information, please visit [Contact US](#)

China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

[43061](#) Series

Mates With

3.96mm Pitch KK or SPOX headers

Use With

SPOX Terminal [5194](#) , [5225](#)

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION