

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0510671000

Status:


Active

Overview:

Mighty-SPOX Connector System

Description:

Mighty-SPOX Wire-to-Wire and Wire-to-Board Housing, 3.50mm Pitch, Positive Lock, 10 Circuits, Natural

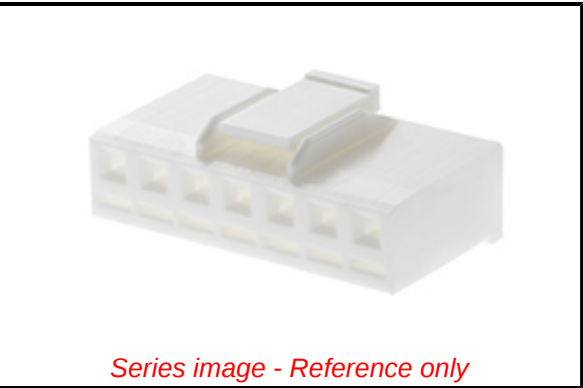

Documents:	
3D Model	Product Specification PS-51067-016-001 (PDF)
3D Model (PDF)	Product Specification PS-51067-017-001 (PDF)
Drawing (PDF)	Product Specification PS-51067-018-001 (PDF)
Product Specification PS-51067-002-001 (PDF)	Product Specification PS-51067-019-001 (PDF)
Product Specification PS-51067-003-001 (PDF)	Product Specification PS-51067-020-001 (PDF)
Product Specification PS-51067-004-001 (PDF)	Product Specification PS-51067-022-001 (PDF)
Product Specification PS-51067-005-001 (PDF)	Product Specification PS-51067-023-001 (PDF)
Product Specification PS-51067-006-001 (PDF)	Packaging Specification SPK-51067-001-001 (PDF)
Product Specification PS-51067-007-001 (PDF)	Packaging Specification SPK-51067-001-002 (PDF)
Product Specification PS-51067-008-001 (PDF)	RoHS Certificate of Compliance (PDF)

Agency Certification	
CSA	LR19980
UL	E29179
General	
Product Family	Crimp Housings
Series	51067
Application	Power, Wire-to-Board, Wire-to-Wire
Overview	Mighty-SPOX Connector System
Product Name	Mighty-SPOX
Taxonomy	Connector Housings
UPC	800753630628
Physical	
Circuits (maximum)	10
Color - Resin	Natural
Flammability	94V-0
Gender	Receptacle
Glow-Wire Capable	No
Material - Resin	Polyester
Net Weight	1946.700/mg
Number of Rows	1
Packaging Type	Bag
Panel Mount	No
Pitch - Mating Interface	3.50mm
Stackable	No
Temperature Range - Operating	-40° to +105°C
Material Info	
Reference - Drawing Numbers	
Packaging Specification	SPK-51067-001-001, SPK-51067-001-002
Product Specification	PS-51067-002-001, PS-51067-003-001, PS-51067-004-001, PS-51067-005-001, PS-51067-006-001, PS-51067-007-001, PS-51067-008-001, PS-51067-016-001, PS-51067-017-001, PS-51067-018-001, PS-51067-019-001, PS-51067-020-001, PS-51067-022-001, PS-51067-023-001
Sales Drawing	SD-51067-XX00-001

EU ELV	
Not Relevant	
EU RoHS	China RoHS
Compliant	
REACH SVHC	
Not Contained Per - D(2022)4187-DC (10 June 2022)	
Halogen-Free	
Status	
Not Low-Halogen	
For more information, please visit Contact US	
China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

51067 Series

Mates With

51114 , 53258 , 53259 , 53265 , 53266

Use With

50217 Crimp Terminals

This document was generated on 10/17/2022

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION