

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0675820000

Status:

Active

Overview:

Serial ATA Connectors

Description:

1.27mm Pitch Crimp Housing for Serial ATA Power Cable Receptacle, 15 Circuits, Black

Documents:

3D Model

3D Model (PDF)

Drawing (PDF)

Packaging Specification PK-67582-001-001 (PDF)

RoHS Certificate of Compliance (PDF)

Agency Certification

UL

E29179

General

Product Family

Series

Application

Overview

Product Name

UPC

Crimp Housings

67582

Power, Wire-to-Board

Serial ATA Connectors

Serial ATA

800756591391

Physical

Circuits (maximum)

Circuits Detail

Color - Resin

Flammability

Gender

Glow-Wire Capable

Keying to Mating Part

Lock to Mating Part

Material - Resin

Net Weight

Number of Rows

Packaging Type

Panel Mount

Pitch - Mating Interface

Pitch - Termination Interface

Polarized to Mating Part

Ports

Stackable

Temperature Range - Operating

15

5 sets terminal per housing

Black

94V-0

Receptacle

No

Yes

No

Polyester

2.160/g

1

Bag

No

1.27mm

1.27mm

No

1

No

-35° to +85°C

Material Info


Reference - Drawing Numbers

Packaging Specification

Sales Drawing

PK-67582-001-001

SD-67582-001-001

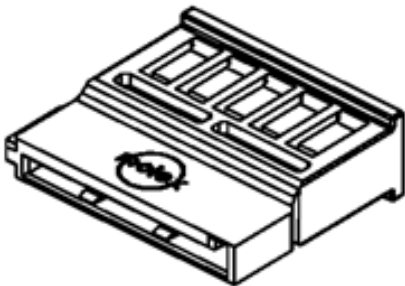

Series image - Reference only

EU ELV

Compliant

EU RoHS

Compliant

REACH SVHC

Not Contained Per - D(2020)9139-DC (19 Jan 2021)

Halogen-Free

Status

Not Low-Halogen

For more information, please visit [Contact US](#)

China RoHS

Green Image

ELV

Compliant

RoHS Phthalates

Not Contained

Search Parts in this Series

67582 Series

Use With

67581 Crimp Terminals

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION