

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0901560143](#)
Status: **Active**
Overview: [C-Grid III Interconnects](#)
Description: 2.54mm Pitch C-Grid III Crimp Housing Single Row, 3 Circuits, Black

Documents:
[3D Model](#) [Application Specification 901190001-AS-000 \(PDF\)](#)
[Drawing \(PDF\)](#) [Packaging Specification PK-90156-0001-001 \(PDF\)](#)
[Product Specification PS-99020-0001-001 \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)


Agency Certification
CSA LR19980
UL E29179

General
Product Family Crimp Housings
Series [90156](#)
Application Signal, Wire-to-Board
Overview [C-Grid III Interconnects](#)
Product Name C-Grid III
UPC 800753668140

Physical
Breakaway No
Circuits (maximum) 3
Color - Resin Black
Gender Receptacle
Glow-Wire Capable No
Lock to Mating Part Yes
Material - Resin PPO
Net Weight 0.293/g
Number of Rows 1
Packaging Type Bag
Panel Mount No
Pitch - Mating Interface 2.54mm
Temperature Range - Operating -55° to +105°C

Material Info

Reference - Drawing Numbers
Application Specification 901190001-AS-000
Packaging Specification PK-90156-0001-001
Product Specification PS-99020-0001-001
Sales Drawing SDA-90156-001

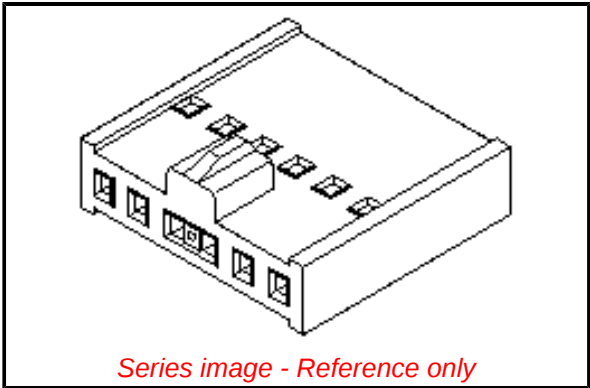

EU ELV
Not Relevant

EU RoHS Compliant REACH SVHC Not Contained Per - D(2020)9139-DC (19 Jan 2021) Halogen-Free Status Low-Halogen For more information, please visit Contact US	China RoHS China ROHS Green Image ELV Not Relevant RoHS Phthalates Not Contained
--	--

Search Parts in this Series
[90156](#) Series

Mates With
[90120](#) , [90121](#) , [90136](#)

Use With
C-Grid III Crimp Terminal [90119](#)
 C-Grid III Pre-Crimped Lead [797582022](#) , [797582023](#)