

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0009507151

Status:

Active

Overview:

KK Interconnect Systems

Description:

KK 3.96mm Crimp Terminal Housing, 15 Circuits, Natural

Documents:

3D Model

3D Model (PDF)

Drawing (PDF)

Product Specification PS-08-50-001 (PDF)

RoHS Certificate of Compliance (PDF)

Agency Certification

CSA

LR19980

UL

E29179

General

Product Family

Crimp Housings

Series

2139

Application

Power, Wire-to-Board

Overview

KK Interconnect Systems

Product Name

KK 396

Taxonomy

Connector Housings

UPC

800753531604

Physical

Circuits (maximum)

15

Color - Resin

Natural

Flammability

94V-2

Gender

Receptacle

Glow-Wire Capable

No

Material - Resin

Nylon

Net Weight

3.840/g

Number of Rows

1

Packaging Type

Bag

Panel Mount

No

Pitch - Mating Interface

3.96mm

Temperature Range - Operating

See Product Specification

Solder Process Data

Lead-freeProcess Capability

N/A

Material Info

Engineering Number

2139-15C


Reference - Drawing Numbers

Product Specification

PS-08-50-001

Sales Drawing

SD-2139-001, SD-2139-002

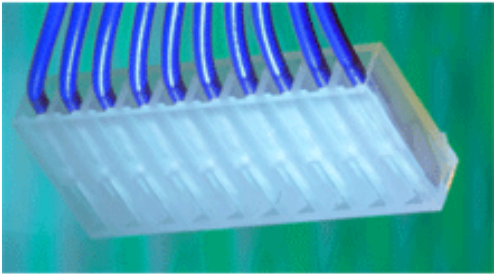

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

China RoHS

REACH SVHC

Not Contained Per -

Halogen-Free

Status

Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

Green Image

ELV

Not Relevant

RoHS Phthalates

Not Contained

Search Parts in this Series

[2139](#) Series

Mates With

KK 396 Headers: [41771](#) , [41772](#) , [41791](#) , [41792](#) , [42491](#) , [42492](#) , KK 396 Breakaway Headers: [41661](#) , [41662](#) , [41671](#) , [41672](#)

Use With

[2478](#) Crimp Terminals for 18-24 AWG, [2578](#) Crimp Terminals for 22-26 AWG

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION