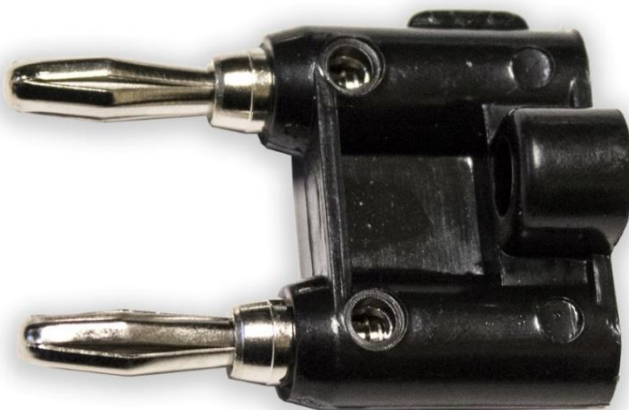


BU-00247-@**(Solderless, Stackable Dual Banana Plug)**

- The BU-00247 is a stackable, dual banana plug with industry standard 0.75" center-to-center plug spacing.
- Overall length 1.625" (41mm), plug center-to-center spacing = 0.75" (19.1mm)
- Wires can be attached via axial setscrews.
- Material: Banana plug Nickel-plated brass
 Spring Nickel-plated phosphor bronze
 Insulator PVC
- Ratings: Current 15 Amps
- Color: The "@" in the model number indicates color. Available colors are:
 -0 Black, -2 Red
- RoHS 3 compliant