

**SUPPRESSOR FOR CONTACTORS**

RC, 230 VAC/DC, 20 VA/W



230 V AC/DC

RC

For other configurations and voltages, please inquire.

[Link to Product](#)

Illustration

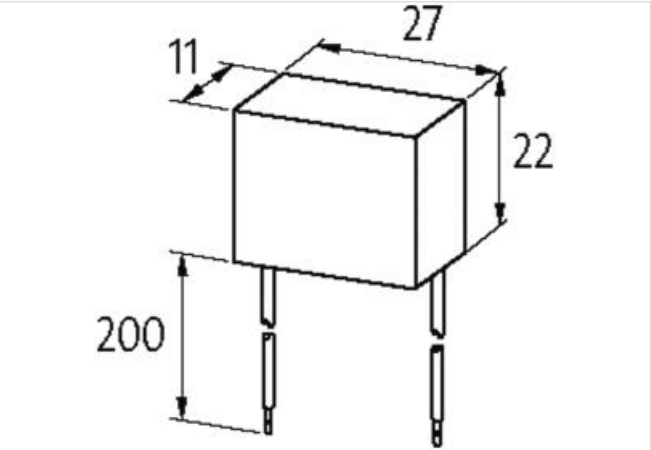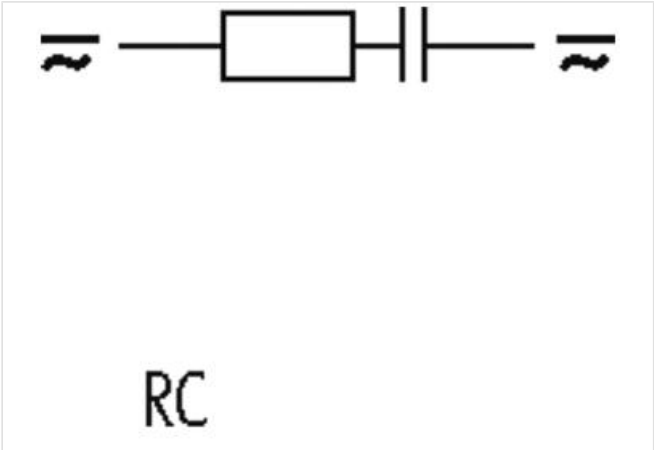

Product may differ from Image



| Commercial data |          |
|-----------------|----------|
| ECLASS-6.0      | 27371013 |
| ECLASS-6.1      | 27371013 |
| ECLASS-7.0      | 27371013 |
| ECLASS-8.0      | 27371013 |
| ECLASS-9.0      | 27371013 |
| ECLASS-10.1     | 27371013 |

|                                                 |                           |
|-------------------------------------------------|---------------------------|
| ECLASS-11.1                                     | 27371013                  |
| ECLASS-12.0                                     | 27371013                  |
| ETIM-5.0                                        | EC002498                  |
| customs tariff number                           | 85363010                  |
| GTIN                                            | 4048879020343             |
| Packaging unit                                  | 1                         |
| <b>Compatibility   Compatible with</b>          |                           |
| Appropriate contactors                          | universal                 |
| <b>Electrical data</b>                          |                           |
| Damping factor                                  | 1.5× UN                   |
| Holding power max.                              | 20 W                      |
| <b>Electrical data   Input</b>                  |                           |
| Input voltage AC min.                           | 110 V                     |
| Input voltage AC max.                           | 253 V                     |
| Input voltage DC min.                           | 110 V                     |
| Input voltage DC max.                           | 253 V                     |
| <b>Installation   Connection</b>                |                           |
| Connection information                          | flexible connection wires |
| <b>Device protection   Media</b>                |                           |
| Flame resistance                                | flame retardant           |
| <b>Mechanical data   Material data</b>          |                           |
| Combustibility class housing (UL94)             | V-0                       |
| Material housing                                | Plastic                   |
| <b>Mechanical data   Mounting data</b>          |                           |
| Height                                          | 22 mm                     |
| Width                                           | 27 mm                     |
| Depth                                           | 11 mm                     |
| <b>Environmental characteristics   Climatic</b> |                           |
| Operating temperature min.                      | -20 °C                    |
| Operating temperature max.                      | 70 °C                     |