

MOTOR SUPPRESSOR

Varistor, 3x575VAC/7,5kW



3× 575 V AC

VDR

Suppressors for other voltages, frequencies, and motor ratings available on request. Do not use RC motor suppressors with frequency inverters.

Link to Product

Illustration

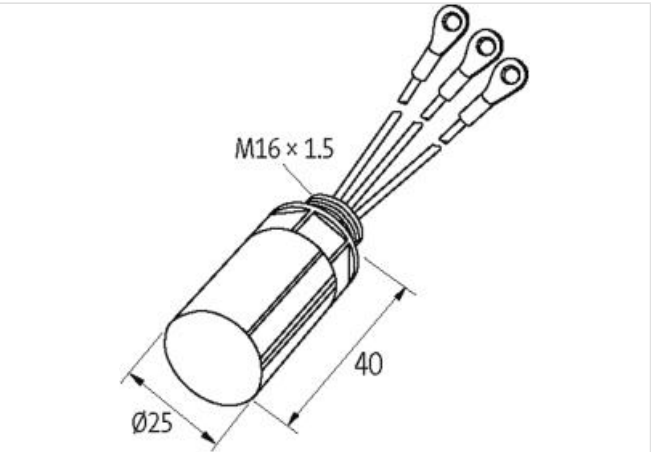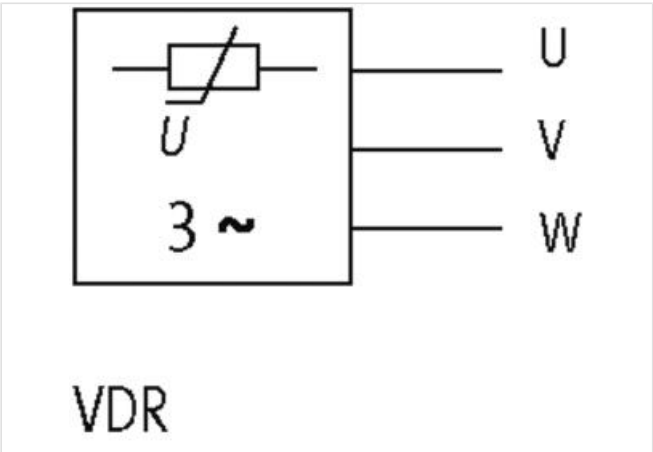

Product may differ from Image



| Commercial data |          |
|-----------------|----------|
| ECLASS-6.0      | 27371013 |
| ECLASS-6.1      | 27371013 |
| ECLASS-7.0      | 27371013 |
| ECLASS-8.0      | 27371013 |
| ECLASS-9.0      | 27371013 |
| ECLASS-10.1     | 27371013 |

|                       |               |
|-----------------------|---------------|
| ECLASS-11.1           | 27371013      |
| ECLASS-12.0           | 27371013      |
| ETIM-5.0              | EC000197      |
| customs tariff number | 85363010      |
| GTIN                  | 4048879018906 |
| Packaging unit        | 1             |

**Electrical data | Input**

|                  |       |
|------------------|-------|
| Input voltage AC | 575 V |
|------------------|-------|

**Installation**

|                               |                     |
|-------------------------------|---------------------|
| Connection cross section max. | 0,5 mm <sup>2</sup> |
|-------------------------------|---------------------|

**Installation | Connection**

|                        |                |
|------------------------|----------------|
| Connection information | Single strands |
| Length single strands  | 100 mm         |
| Ring terminals         | M6isolated     |

**Device protection | Media**

|                  |                 |
|------------------|-----------------|
| Flame resistance | flame retardant |
|------------------|-----------------|

**Mechanical data | Material data**

|                                     |                   |
|-------------------------------------|-------------------|
| Combustibility class housing (UL94) | V-0               |
| Material housing                    | Plastic           |
| Material potting compound           | 2-component epoxy |

**Mechanical data | Mounting data**

|                            |                  |
|----------------------------|------------------|
| Mounting method            | inserted         |
| Suitable for mounting type | Motorklemmkasten |
| Height                     | 25 mm            |
| Width                      | 25 mm            |
| Depth                      | 40 mm            |

**Environmental characteristics | Climatic**

|                            |        |
|----------------------------|--------|
| Operating temperature min. | -20 °C |
| Operating temperature max. | 60 °C  |