

MODLINK MSVD CABINET POWER OUTLETS

VDE orange 250V AC / 16 A


Germany (VDE) orange
for installing in front of main switch
Spring clamp terminals

Link to Product

Illustration



Product may differ from Image

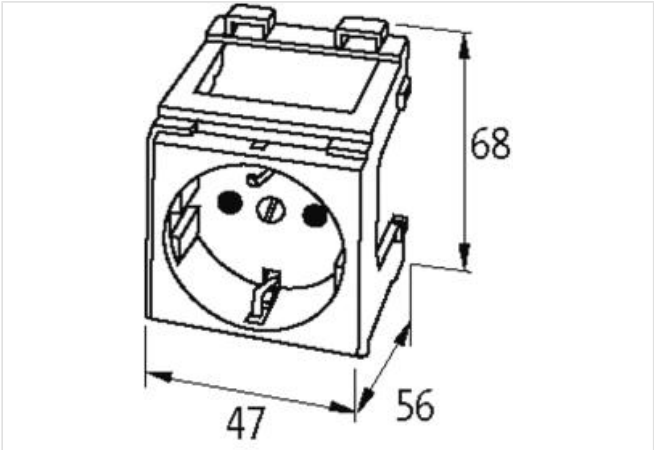

Commercial data

ECLASS-6.0	27143423
ECLASS-6.1	27142305
ECLASS-7.0	27142305
ECLASS-8.0	27142305
ECLASS-9.0	27142305
ECLASS-10.1	27142305
ECLASS-11.1	27142305
ECLASS-12.0	27142305
ETIM-5.0	EC002625
customs tariff number	85366990
GTIN	4048879031271
Packaging unit	1

Electrical data | Supply

Operating voltage AC	250 V
Operating current min.	10 A
Operating current max.	16 A

Installation

Connection cross section max.	2,5 mm ²
AWG number max.	14

Installation | Connection

Connection Spring clamp terminals FK

Installation | Pin assignment

No. of poles	2 + PE
Connections per pole	2
Protection contact present	yes

Mechanical data | Mounting data

Mounting method	Snap-in connector
Suitable for mounting type	Mounting rail TH35
Height	68 mm
Width	47 mm
Depth	56 mm