



**Bus terminating plug M12 male A-cod.**

CUBE67


Cube67  
Terminating resistor  
Male  
M12, 6-pole  
A-coded  
Plastic housings with good resistance against chemicals and oils.  
The resistance to aggressive media should be individually tested for your application. Further details on request.

[Link to Product](#)

Illustration

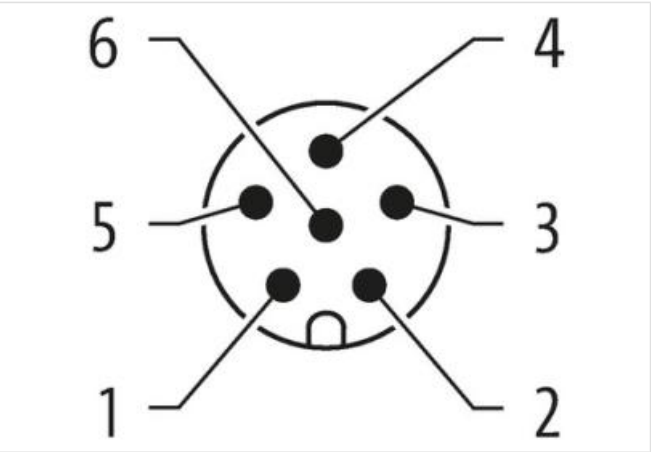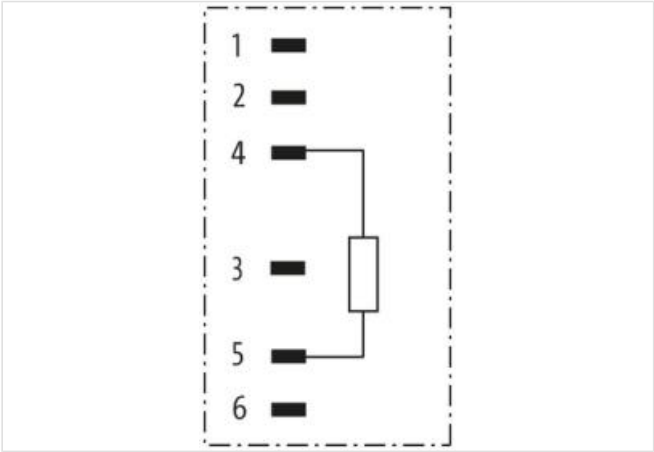

Product may differ from Image

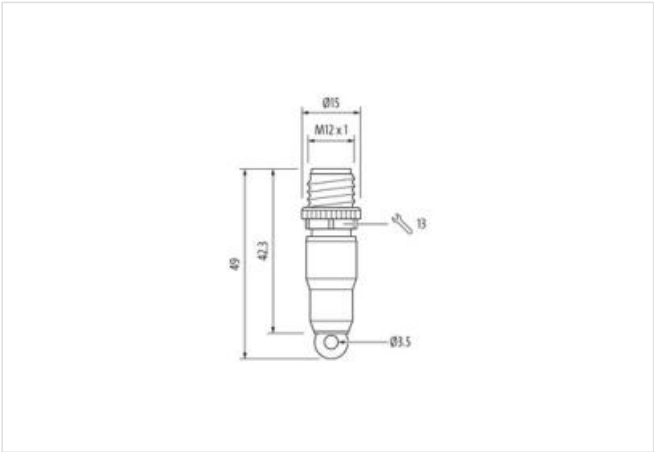

Side 1	
Tightening torque	0,6 Nm
Family construction form	M12
Degree of protection (EN IEC 60529)	IP67

Commercial data	
ECLASS-6.0	19070403
ECLASS-7.0	19070403
ECLASS-8.0	19070403
ECLASS-9.0	19070403
ECLASS-10.1	27440190
ECLASS-11.1	27440190
ECLASS-12.0	27440190
ETIM-5.0	EC001855
customs tariff number	85332100
GTIN	4048879196963
Packaging unit	1
Electrical data   Supply	
Operating voltage DC max.	30 V
Operating voltage DC max. (UL-listed)	30 V
Current operating per contact max.	4 A
Device protection   Electrical	
Additional condition protection degree	inserted, screwed
Mechanical data   Mounting data	
Mounting method	inserted, screwed, Shaking protection
Environmental characteristics   Climatic	
Operating temperature min.	-25 °C
Operating temperature max.	85 °C