



MICO FUSE 250 FUSE HOLDER 5X20MM 8 CHANNELS

IN: 250V AC/DC OUT: 250V AC/DC / 6A AC/DC

MICO FUSE 250
8 channels
Total current: max. 40 A

[Link to Product](#)

Illustration

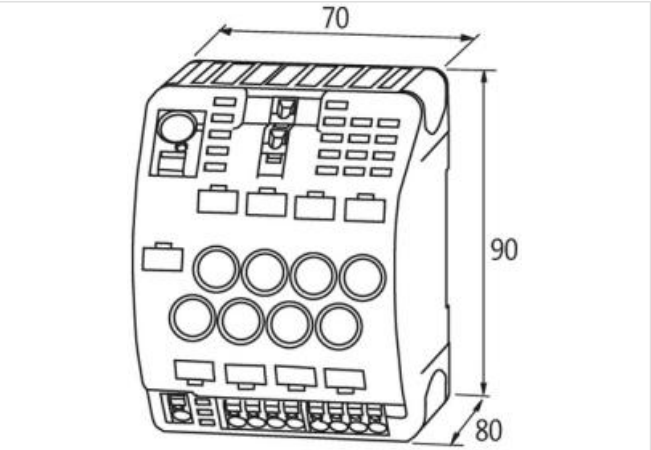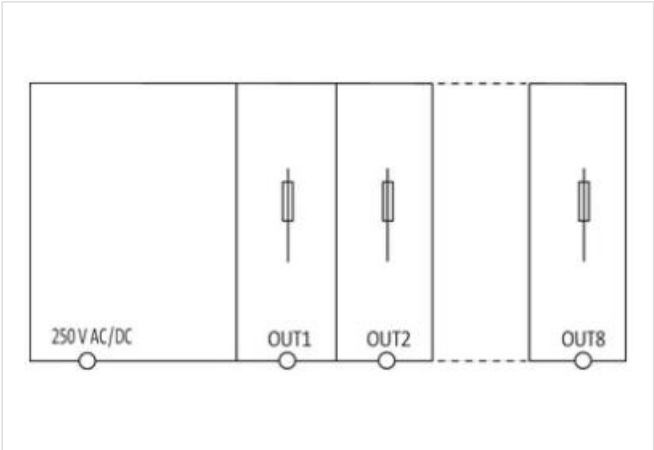

Product may differ from Image



Commercial data	
ECLASS-6.0	27371802
ECLASS-6.1	27142107
ECLASS-7.0	27142121
ECLASS-8.0	27142121
ECLASS-9.0	27142121
ECLASS-10.1	27142121

ECLASS-11.1	27142121
ECLASS-12.0	27142121
ETIM-5.0	EC001440
customs tariff number	85363030
GTIN	4048879335270
Packaging unit	1

Electrical data | Supply

Operating voltage AC max.	250 V
Operating voltage DC max.	250 V
Operating current max.	6 A
Total current max.	40 A

Installation

Connection cross-section inputs max.	16 mm ²
Connection cross-section outputs min.	0,5 mm ²
Connection cross-section outputs max.	4 mm ²

Mechanical data | Mounting data

Mounting method	geschnappt
Suitable for mounting type	Mounting rail TH35, (EN 60715)
Height	90 mm
Width	70 mm
Depth	80 mm

Environmental characteristics | Climatic

Operating temperature min.	-25 °C
Operating temperature max.	55 °C
Derating from	40 °C

Connection type 3

Connection	Spring clamp terminals FK
Family construction form	terminal
Gender	female
Color contact carrier	green
No. of poles	1
PIN 1	In
Connection	Spring clamp terminals FK
Family construction form	terminal
Gender	female
Color contact carrier	green
No. of poles	4
PIN 1	Out 1
PIN 2	Out 2
PIN 3	Out 3
PIN 4	Out 4
Connection	Spring clamp terminals FK
Family construction form	terminal
Gender	female
Color contact carrier	green
No. of poles	4
PIN 1	Out 5
PIN 2	Out 6
PIN 3	Out 7
PIN 4	Out 8