

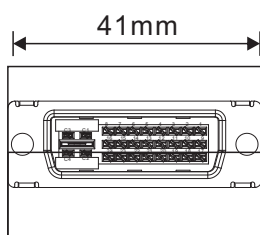


DVI-I, Dual Link Connector modular

Item No. 2001C223

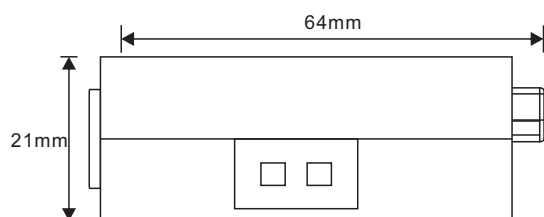

1	2	3	4	5	6	7	8	9	10
TMDS Data2-	TMDS Data2+	TMDS Data2/4 Shield	TMDS Data4-	TMDS Data4+	DDC Clock	DDC Data	Analog Vertical Sync	TMDS Data1-	TMDS Data1+
11	12	13	14	15	16	17	18	19	20
TMDS Data1/3 Shield	TMDS Data3-	TMDS Data3+	+5V Power	Ground (return for +5V, Hot Plug Detect)	Hot Plug Detect	TMDS Data0-	TMDS Data0+	TMDS Data0/5 Shield	TMDS Data5-
21	22	23	24	C1	C2	C3	C4	C5	
TMDS Data5+	TMDS Clock Shield	TMDS Clock+	TMDS Clock-	Analog Red	Analog Green	Analog Blue	Horizontal Sync Analog	Analog Ground (analog RGB return)	

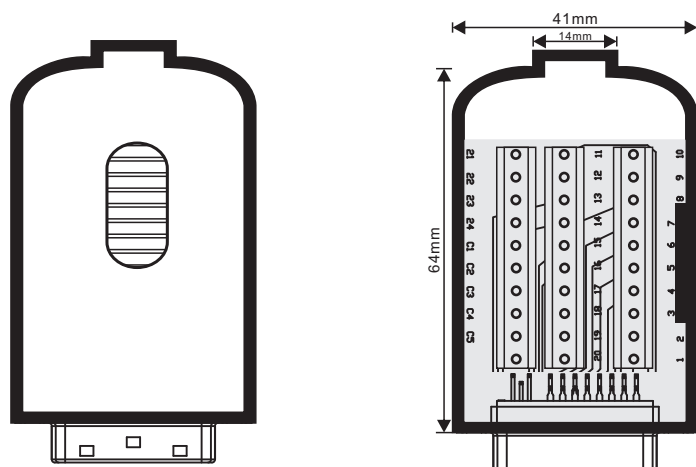

Included accessories
1x Screw driver
1x Cable strain Relief
2x Fastening screw



Material:
Housing: PP
Insulator: PBT
Connector shell: SPCC with plated Ni 60μ min.
Contact: Brass with plated Au 1μ
Technical:
Voltage rating: 40V max.
Current rating: 1.5A max.
Contact resistance: 20mΩ max.
Insulation resistance: 500MΩ min.
Dielectric withstanding voltage: 500V/AC(R.M.S)
Operation temperature: -20 ~85°C