

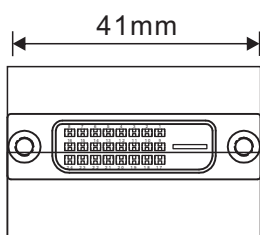


## DVI-D Female Connector modular

Item No. 2001C228

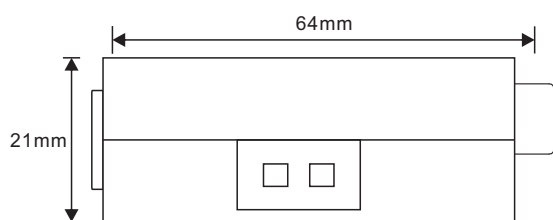

Included accessories  
1x Screw driver  
1x Cable strain Relief  
2x Fastening screw

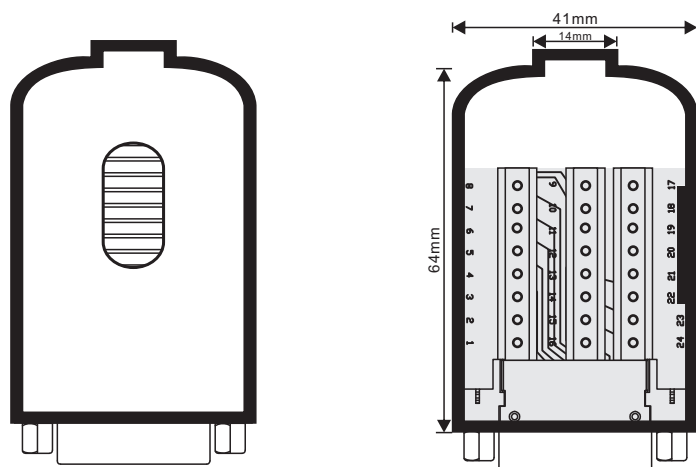

1	2	3	4	5	6	7	8	9	10
TMDS Data2-	TMDS Data2+	TMDS Data2/4 Shield	TMDS Data4-	TMDS Data4+	DDC Clock	DDC Data	Analog Vertical Sync	TMDS Data1-	TMDS Data1+
11	12	13	14	15	16	17	18	19	20
TMDS Data1/3 Shield	TMDS Data3-	TMDS Data3+	+5V Power	Ground (return for +5V, Hsync, and Vsync)	Hot Plug Detect	TMDS Data0-	TMDS Data0+	TMDS Data0/5 Shield	TMDS Data5-
21	22	23	24						
TMDS Data5+	TMDS Clock Shield	TMDS Clock+	TMDS Clock-						

Material:  
Housing: PP  
Insulator: PBT  
Connector shell: SPCC with plated Ni 40μ min.  
Contact: Brass with plated Au1μ  
Technical:  
Voltage rating: 40V max.  
Current rating: 1.5A max.  
Contact resistance: 30mΩ max.  
Insulation resistance: 1000MΩ min.  
Dielectric withstanding voltage: 500V/AC(R.M.S)  
Operation temperature: -20 ~85°C