



224pcs Cable Gland Set, Metric Thread, Grey

Item No. 2009CA109

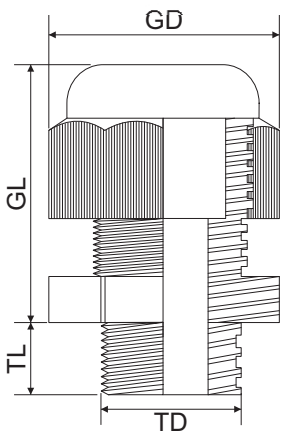

Thread	Cable range (ømm)	TD (ømm)	TL (mm)	GL (mm)	GD (ømm)	Pcs.
M12	3.0 ~ 6.5	11.8	9.0	21.0	17.0	40
M16	4.0 ~ 8.0	15.7	9.0	23.5	20.8	40
M20	6.0 ~ 12.0	17.6	9.0	27.0	26.0	15
M25	13.0 ~ 18.0	24.8	12.5	32.0	35.6	12
M32	16.0 ~ 21.0	31.8	12.5	34.1	37.9	5

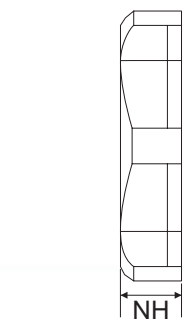

Thread	NH (mm)	Pcs.
M12 x 1.5	4.50	40
M16 x 1.5	4.70	40
M20 x 1.5	5.20	15
M25 x 1.5	6.10	12
M32 x 1.5	6.70	5

Specification

Material:

Gland - PA 66

Seal - NBR

Color: Light Grey (RAL7035)

Thread type: Metric

Waterproof class: IP68

Working temperature: -20 ~ 80°C