

15-Pin D-sub terminal connector modular



2010C250 - Male connector with jackscrew nut connection



2010C251 - Female connector with jackscrew nut connection



2010C252 - Male connector with locking screw connection



2010C253 - Female connector with locking screw connection

Included accessories
1x Screw driver
1x Cable strain Relief
2x Fastening screw



Material:

Housing: PP

Connector insulator: PBT+30%GF (UL94V-0)

Contact: Brass

Contact plated: Nickel

Connector shell plated: Cu60μ/Ni100-120μ



Technical:

Contact current rating: 5A max.

Insulation resistance: 1000MΩ min. at 500V/DC


Dielectric withstanding voltage: 500V/AC(R.M.S)/1min.

Operation temperature: -20 ~85°C

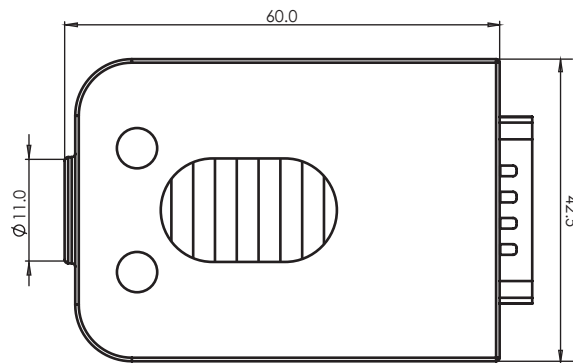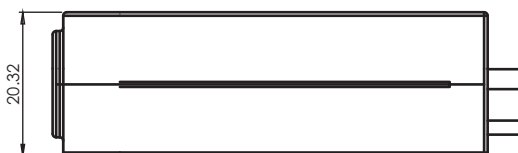


mm ±0.2

 Male



Female

 

- 1 RSSI analog input
- 2 Enable switch input
- 3 Tach signal input
- 4 Heading switch input
- 5 IrDA output
- 6 RS232 output
- 7 -V inout
- 8 +DC input
- 9 Squeal tone output
- 10 Ground
- 11 Ground
- 12 Ground
- 13 Ground
- 14 Ground
- 15 +DC