

VGA 3+9 terminal connector modular



2010C254 - Male connector with jackscrew nut connection



2010C255 - Female connector with jackscrew nut connection



2010C256 - Male connector with locking screw connection



2010C257 - Female connector with locking screw connection

Included accessories
1x Screw driver
1x Cable strain Relief
2x Fastening screw



Material:

Housing: PP

Connector insulator: PBT+30%GF (UL94V-0)

Contact: Brass

Contact plated: Nickel

Connector shell plated: Cu60µ/Ni100-120µ


Technical:

Contact current rating: 5A max.


Insulation resistance: 1000MΩ min. at 500V/DC

Dielectric withstanding voltage: 500V/AC(R.M.S)/1min.


Operation temperature: -20 ~85°C

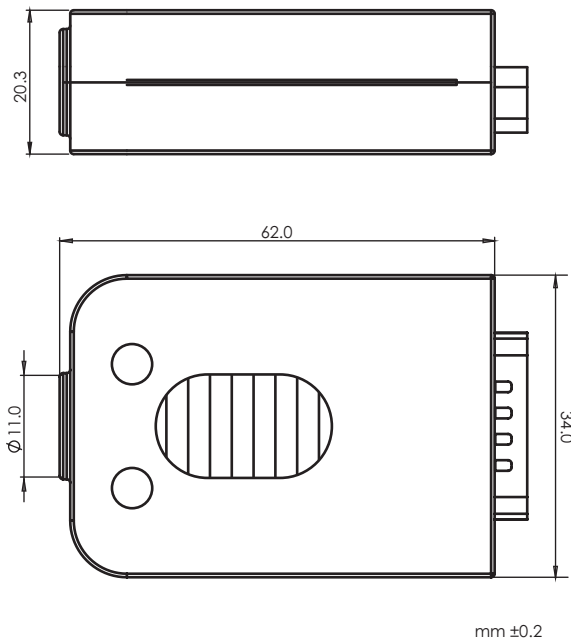

Male

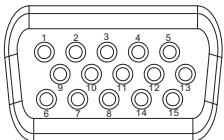

Female

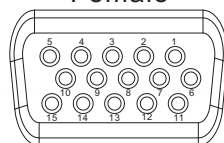

- 1 RED video
- 2 GREEN video
- 3 BLUE video
- 4 ID2/RES
- 5 GND
- 6 RED_RTN
- 7 GREEN_RTN
- 8 BLUE_RTN
- 9 KEY/PWR
- 10 GND
- 11 ID0/RES
- 12 ID1/SDA
- 13 HSync
- 14 VSync
- 15 ID3/SCL

mm ±0.2