

20pcs Quick Splice Terminal Connector Set

 
2011C402 - Red

2011C403 - Blue

2011C404 - Yellow







Male blade Plug Terminal
Insulator material: PA (Nylon)
Terminal material: Tinned Brass
Working Temperature: 105°C max.



Dimension						A.W.G(mm ²)	Rating (max.)		Color	Contents
W	F	L	B	Dø	Cø		Voltage	Current		
6.35	7.7	24.0	11.0	5.0	1.7	22-18 (0.5-1.0)	300 V/AC	10A	Red	10pcs
6.35	7.7	24.0	11.0	5.5	2.3	16-14 (1.5-2.5)	300 V/AC	15A	Blue	10pcs
6.35	7.7	25.0	13.0	7.3	3.4	12-10 (4.0-6.0)	300 V/AC	20A	Yellow	10pcs

T-Tap Splice
Insulator material: PP
Terminal material: Tinned Brass
Working Temperature: 75°C max.

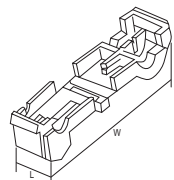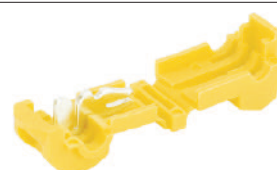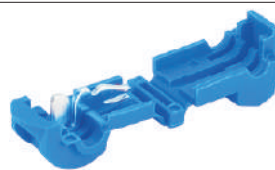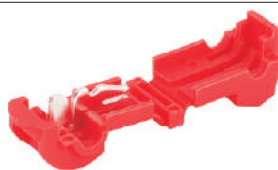

Dimension (L x W)	A.W.G (mm ²)	Rating (max.)		Color	Contents
		Voltage	Current		
37 x 10 mm	22-18 (0.5-1.0)	300 V/AC	9A	Red	10pcs
37 x 10 mm	16-14 (1.5-2.5)	300 V/AC	15A	Blue	10pcs
37 x 10 mm	12-11 (2.5-4.0)	300 V/AC	20A	Yellow	10pcs

