

## Self Adjusting Wire-End Ferrule Crimping Pliers Range 0.25...10 mm<sup>2</sup> (AWG 23-7) Bundle Item-No.: 23T036


This crimping tool is particularly suitable for hobbyists, craftsmen, field service, service workshops, electronics technicians and laboratory needs. The crimping tool is optimally matched to the field of application and has an automatic adjustment to the sleeve diameters between 0.25 and 10 sqmm. The square crimping claw ensures a safe crimping process, the ergonomic handle fits well in the hand and allows comfortable working. The pliers have an adjustment option for fine adjustment of the compressive force and a quick locking safety lock.



### Technical Specifications

Four-mandrel press claw • Automatic adjustment • Fine adjustment ratchet pressure • Quick release safety lock • ergonomic handle • Range from 0.25 to 10 mm<sup>2</sup> (AWG 23 ... 7) • Weight: 363 g.

### Usage example

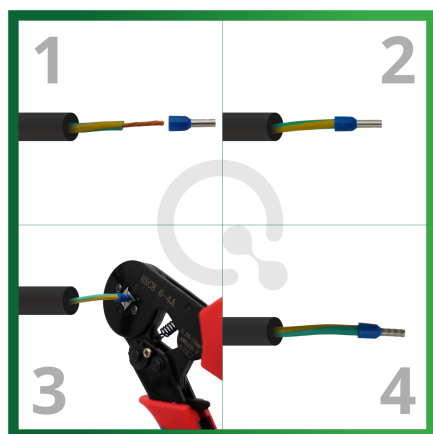

Application by qualified electricians only.

Works best with Quadrios` ferrule assortment sets.






RoHS



REACH  
Compliant

## Wire ferrules (insulated) assortment 23T036 0.5 mm<sup>2</sup> ... 2.5 mm<sup>2</sup> 400 pcs set

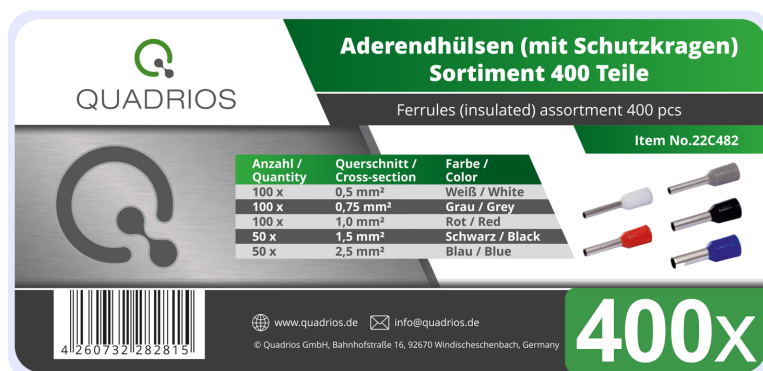

Quadrios wire end ferrules guarantee optimal crimp connections in conjunction with fitting crimping tools. This set includes wire end ferrules with plastic collars based on the DIN 46228 color code. The ferrules are especially suitable for hobbyists, craftsmen, field service, service workshops, electronics technicians and laboratory needs. Optimal for use with suitable Quadrios wire end ferrule crimping pliers. Refill packs available – see table down below.

**Technical data:** Voltage (max.): 440 V, Material: polyamide (collar) / Material: copper • Plating: tin • Color: DIN color code • Content: 50x 1.5 mm<sup>2</sup>, barrel-length 8 mm, black • 50x 2.5 mm<sup>2</sup>, barrel-length 8 mm, blue • 100x 1.0 mm<sup>2</sup>, barrel-length 8 mm, red • 100x 0.5 mm<sup>2</sup>, barrel-length 8 mm, white • 100x 0.75 mm<sup>2</sup>, barrel-length 8 mm, grey.




Substitute ferrules in 100 pcs units are available:

Part No.	Description	Cross-section	Barrel length	Color	Inner diameter	EAN	Content
22C425	Wire ferrules 0.5 mm <sup>2</sup> , plastic-collar white	0.5 mm <sup>2</sup>	8 mm	White	1.1 mm	4260732280859	100 pcs
22C426	Wire ferrules 0.75 mm <sup>2</sup> , plastic-collar grey	0.75 mm <sup>2</sup>	8 mm	Grey	1.3 mm	4260732280866	100 pcs
22C427	Wire ferrules 1 mm <sup>2</sup> , plastic-collar red	1 mm <sup>2</sup>	8 mm	Red	1.5 mm	4260732280873	100 pcs
22C428	Wire ferrules 1.5 mm <sup>2</sup> , plastic-collar black	1.5 mm <sup>2</sup>	8 mm	Black	1.8 mm	4260732280880	100 pcs
22C429	Wire ferrules 2.5 mm <sup>2</sup> , plastic-collar blue	2.5 mm <sup>2</sup>	8 mm	Blue	2.3 mm	4260732280897	100 pcs
22C430	Wire ferrules 4 mm <sup>2</sup> , plastic-collar grey	4 mm <sup>2</sup>	9 mm	Grey	2.9 mm	4260732280903	100 pcs
22C431	Wire ferrules 6 mm <sup>2</sup> , plastic-collar yellow	6 mm <sup>2</sup>	12 mm	Yellow	3.6 mm	4260732280910	100 pcs
22C432	Wire ferrules 10 mm <sup>2</sup> , plastic-collar red	10 mm <sup>2</sup>	12 mm	Red	4.6 mm	4260732280927	100 pcs
22C433	Twin-Wire ferrules 0.5 mm <sup>2</sup> , plastic-collar white	0.5 mm <sup>2</sup>	8 mm	White	2x 1.1 mm	4260732280934	100 pcs
22C434	Twin-Wire ferrules 0.75 mm <sup>2</sup> , plastic-collar grey	0.75 mm <sup>2</sup>	8 mm	Grey	2x 1.3 mm	4260732280941	100 pcs
22C435	Twin-Wire ferrules 1 mm <sup>2</sup> , plastic-collar red	1 mm <sup>2</sup>	8 mm	Red	2x 1.5 mm	4260732280958	100 pcs
22C436	Twin-Wire ferrules 1.5 mm <sup>2</sup> , plastic-collar black	1.5 mm <sup>2</sup>	8 mm	Black	2x 1.8 mm	4260732280965	100 pcs
22C437	Twin-Wire ferrules 2.5 mm <sup>2</sup> , plastic-collar blue	2.5 mm <sup>2</sup>	10 mm	Blue	2x 2.3 mm	4260732280972	100 pcs
22C438	Twin-Wire ferrules 4 mm <sup>2</sup> , plastic-collar grey	4 mm <sup>2</sup>	12 mm	Grey	2x 2.9 mm	4260732280989	100 pcs
22C439	Twin-Wire ferrules 6 mm <sup>2</sup> , plastic-collar yellow	6 mm <sup>2</sup>	14 mm	Yellow	2x 3.6 mm	4260732280996	100 pcs
22C440	Twin-Wire ferrules 10 mm <sup>2</sup> , plastic-collar red	10 mm <sup>2</sup>	14 mm	Red	2x 4.6 mm	4260732281009	100 pcs

Connection only by qualified electricians!



## Twin Wire ferrules (ins.) assortment 23T036 2x 0.5 mm<sup>2</sup> ... 2x 1.5 mm<sup>2</sup> 200 pcs set

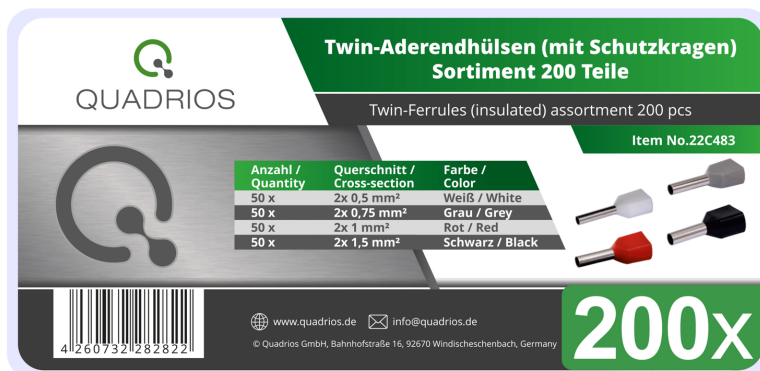

Quadrios wire end ferrules guarantee optimal crimp connections in conjunction with fitting crimping tools. This set includes duo-wire end ferrules with plastic collars based on the DIN 46228 color code. The ferrules are especially suitable for hobbyists, craftsmen, field service, service workshops, electronics technicians and laboratory needs. Optimal for use with suitable Quadrios wire end ferrule crimping pliers. Refill packs available – see table down below.

**Technical data:** Voltage (max.): 440 V, Material: polyamide (collar) / Material: copper • Plating: tin • Color: DIN color code • Content: 50x 2x1.5 mm<sup>2</sup>, barrel-length 8 mm, black • 50x 2x1.0 mm<sup>2</sup>, barrel-length 8 mm, red • 50x 2x0.5 mm<sup>2</sup>, barrel-length 8 mm, white • 50x 2x0.75 mm<sup>2</sup>, barrel-length 8 mm, grey.



Substitute ferrules in 100 pcs units are available:


Part No.	Description	Cross-section	Barrel length	Color	Inner diameter	EAN	Content
22C425	Wire ferrules 0.5 mm <sup>2</sup> , plastic-collar white	0.5 mm <sup>2</sup>	8 mm	White	1.1 mm	4260732280859	100 pcs
22C426	Wire ferrules 0.75 mm <sup>2</sup> , plastic-collar grey	0.75 mm <sup>2</sup>	8 mm	Grey	1.3 mm	4260732280866	100 pcs
22C427	Wire ferrules 1 mm <sup>2</sup> , plastic-collar red	1 mm <sup>2</sup>	8 mm	Red	1.5 mm	4260732280873	100 pcs
22C428	Wire ferrules 1.5 mm <sup>2</sup> , plastic-collar black	1.5 mm <sup>2</sup>	8 mm	Black	1.8 mm	4260732280880	100 pcs
22C429	Wire ferrules 2.5 mm <sup>2</sup> , plastic-collar blue	2.5 mm <sup>2</sup>	8 mm	Blue	2.3 mm	4260732280897	100 pcs
22C430	Wire ferrules 4 mm <sup>2</sup> , plastic-collar grey	4 mm <sup>2</sup>	9 mm	Grey	2.9 mm	4260732280903	100 pcs
22C431	Wire ferrules 6 mm <sup>2</sup> , plastic-collar yellow	6 mm <sup>2</sup>	12 mm	Yellow	3.6 mm	4260732280910	100 pcs
22C432	Wire ferrules 10 mm <sup>2</sup> , plastic-collar red	10 mm <sup>2</sup>	12 mm	Red	4.6 mm	4260732280927	100 pcs
22C433	Twin-Wire ferrules 0.5 mm <sup>2</sup> , plastic-collar white	0.5 mm <sup>2</sup>	8 mm	White	2x 1.1 mm	4260732280934	100 pcs
22C434	Twin-Wire ferrules 0.75 mm <sup>2</sup> , plastic-collar grey	0.75 mm <sup>2</sup>	8 mm	Grey	2x 1.3 mm	4260732280941	100 pcs
22C435	Twin-Wire ferrules 1 mm <sup>2</sup> , plastic-collar red	1 mm <sup>2</sup>	8 mm	Red	2x 1.5 mm	4260732280958	100 pcs
22C436	Twin-Wire ferrules 1.5 mm <sup>2</sup> , plastic-collar black	1.5 mm <sup>2</sup>	8 mm	Black	2x 1.8 mm	4260732280965	100 pcs
22C437	Twin-Wire ferrules 2.5 mm <sup>2</sup> , plastic-collar blue	2.5 mm <sup>2</sup>	10 mm	Blue	2x 2.3 mm	4260732280972	100 pcs
22C438	Twin-Wire ferrules 4 mm <sup>2</sup> , plastic-collar grey	4 mm <sup>2</sup>	12 mm	Grey	2x 2.9 mm	4260732280989	100 pcs
22C439	Twin-Wire ferrules 6 mm <sup>2</sup> , plastic-collar yellow	6 mm <sup>2</sup>	14 mm	Yellow	2x 3.6 mm	4260732280996	100 pcs
22C440	Twin-Wire ferrules 10 mm <sup>2</sup> , plastic-collar red	10 mm <sup>2</sup>	14 mm	Red	2x 4.6 mm	4260732281009	100 pcs

Connection only by qualified electricians!

## Wire ferrules assortment 23T036

### 0.5 mm<sup>2</sup> ... 6 mm<sup>2</sup>

### 500 pcs set

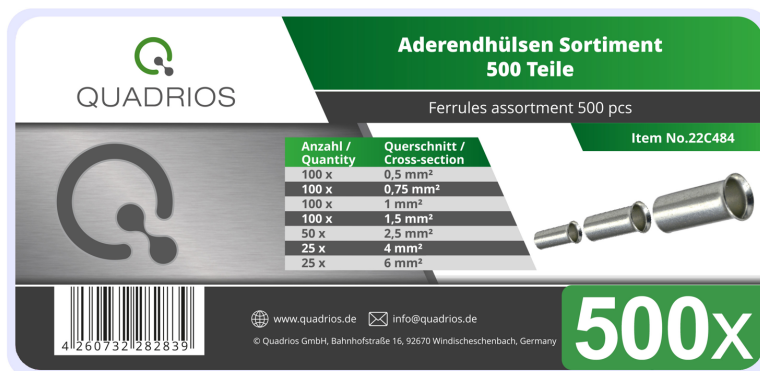

Quadrios wire end ferrules guarantee optimal crimp connections in conjunction with fitting crimping tools. This set includes uninsulated wire end ferrules for maximum flexibility. The ferrules are especially suitable for hobbyists, craftsmen, field service, service workshops, electronics technicians and laboratory needs. Optimal for use with suitable Quadrios wire end ferrule crimping pliers. Refill packs available – see table down below.

**Technical data:** Voltage (max.): 440 V, Material: copper • Plating: tin • Type: uninsulated / without plastic collar • Content: 100x 0.5 mm<sup>2</sup>, barrel-length 8 mm • 100x 0.75 mm<sup>2</sup>, barrel-length 8 mm • 100x 1.0 mm<sup>2</sup>, barrel-length 8 mm • 100x 1.5 mm<sup>2</sup>, barrel-length 8 mm • 50x 2.5 mm<sup>2</sup>, barrel-length 8 mm • 25x 4.0 mm<sup>2</sup>, barrel-length 8 mm • 25x 6.0 mm<sup>2</sup>, barrel-length 8 mm.



Substitute ferrules in 100 pcs units are available:

Part No.	Description	Cross-section	Bezel diameter	Inner diameter	Outer diameter	Barrel length	EAN	Content
22C471	Ferrules, uninsulated 0.25 mm <sup>2</sup>	0.25 mm <sup>2</sup>	1.5 mm	0.8 mm	1.1 mm	6 mm	4260732282709	100 pcs
22C472	Ferrules, uninsulated 0.34 mm <sup>2</sup>	0.34 mm <sup>2</sup>	1.5 mm	0.8 mm	1.1 mm	6 mm	4260732282716	100 pcs
22C473	Ferrules, uninsulated 0.5 mm <sup>2</sup>	0.5 mm <sup>2</sup>	1.7 mm	1 mm	1.3 mm	6 mm	4260732282723	100 pcs
22C474	Ferrules, uninsulated 0.75 mm <sup>2</sup>	0.75 mm <sup>2</sup>	1.9 mm	1.2 mm	1.5 mm	6 mm	4260732282730	100 pcs
22C475	Ferrules, uninsulated 1 mm <sup>2</sup>	1 mm <sup>2</sup>	2.2 mm	1.4 mm	1.7 mm	6 mm	4260732282747	100 pcs
22C476	Ferrules, uninsulated 1.5 mm <sup>2</sup>	1.5 mm <sup>2</sup>	2.5 mm	1.7 mm	2 mm	8 mm	4260732282754	100 pcs
22C477	Ferrules, uninsulated 2.5 mm <sup>2</sup>	2.5 mm <sup>2</sup>	3.3 mm	2.3 mm	2.6 mm	8 mm	4260732282761	100 pcs
22C478	Ferrules, uninsulated 4 mm <sup>2</sup>	4 mm <sup>2</sup>	3.9 mm	2.8 mm	3.2 mm	12 mm	4260732282778	100 pcs
22C479	Ferrules, uninsulated 6 mm <sup>2</sup>	6 mm <sup>2</sup>	4.7 mm	3.5 mm	3.9 mm	12 mm	4260732282785	100 pcs
22C480	Ferrules, uninsulated 10 mm <sup>2</sup>	10 mm <sup>2</sup>	5.8 mm	4.5 mm	4.9 mm	12 mm	4260732282792	100 pcs
22C481	Ferrules, uninsulated 16 mm <sup>2</sup>	16 mm <sup>2</sup>	7.2 mm	5.8 mm	6.2 mm	12 mm	4260732282808	100 pcs

Connection only by qualified electricians!