

Adapter

- zum Adaptieren von Ø 4 mm-System auf Ø 4 mm-Sicherheits-System

Best.-Nr. A 40 - 40 S Ni / ..(Farbe)


- Kontaktteile **vernickelt**
- Isolierteile PA 6.6 (Polyamid)
- **Farben** siehe Tabelle

Adapter

- for adaption from Ø 4 mm system to Ø 4 mm safety system

Order No. A 40 - 40 S Ni / ..(colour)

- contact parts **nickel-plated**
- insulation PA 6.6 (Polyamid)
- **colours** see table

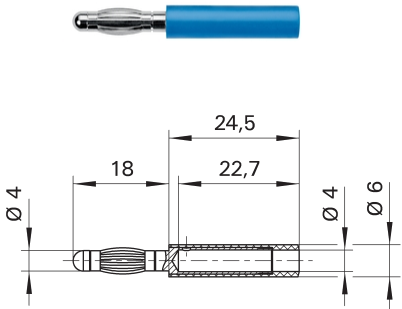

Ø 4 mm

Allgemeine Angaben	
Best.-Nr. ¹⁾	A 40 - 40 S Ni / ..(Farbe) Kontaktteile vernickelt
Farben	schwarz, rot, blau, gelb, grün, grau, braun, weiß, violett
Technische Daten	
Anschluss	Steckbuchse
Durchgangswiderstand	6 mΩ
Bemessungsspannung ²⁾	30 V _{AC} / 60 V _{DC}
Bemessungsstrom ²⁾	32 A
Temperatur-Einsatzbereich	von -25 °C bis +80 °C

¹⁾ andere Kontaktoberflächen, Farben und Ausführungen auf Anfrage
²⁾ bei normalen Umgebungstemperaturen

General information	
Order No. ¹⁾	A 40 - 40 S Ni / ..(colour) contact parts nickel-plated
colours	black, red, blue, yellow, green, grey, brown, white, purple
Technical data	
terminal	inline socket
transition resistance	6 mΩ
rated voltage ²⁾	30 V _{AC} / 60 V _{DC}
rated current ²⁾	32 A
operating temperature	from -25 °C to +80 °C

¹⁾ other contact platings, colours and designs on request
²⁾ at normal ambient temperatures