
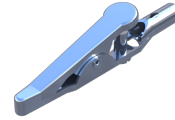


Crocodile clips

AGS 20

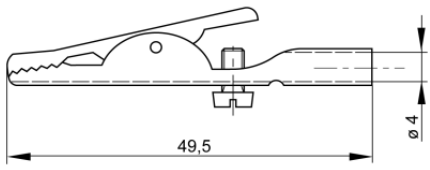

Product	AGS 20
description	Nickel-plated steel alligator clip. Clamping range up to a maximum bolt diameter 5 mm. 4 mm diameter socket connection, connection possible by terminal screw and solder connection.
operating instruction	BA420
Articlenummer	603006001 Ni
drawing	
	
technical data	
connection	unsprung socket 4 mm, solder connection, screw terminal
rated voltage	30 VAC / 60 VDC
measurement cat. acc. to IEC 61010	O ⁽²⁾
rated current (consider derating curve)	4 A
material socket	steel, nickel plated
temperature range acc. To IEC61010 ⁽¹⁾	-25 °C to +100 °C
clamping range	5 mm

⁽¹⁾ contact the manufacturer for applications at deviating temperature ranges

⁽²⁾ without rated measurement category, for other circuits that are not directly connected to mains

stand: 21.06.2022

stand: 21.06.2022

4 mm system