
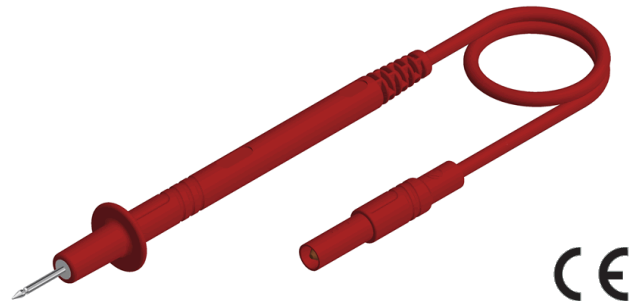


Measuring leads

PL 2700 S

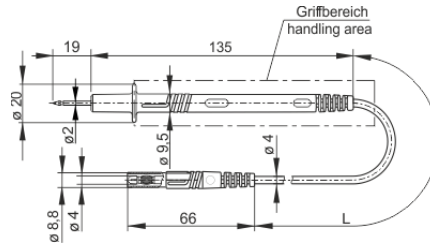

Product	PL 2700 S
description	Safety test lead with test probe. Tip for penetration of oxide layers and 4 mm diameter safety connector with straight outlet. Highly flexible, double insulated stranded lead, shatter-proof grip sleeve and lead. Built in color indicator for easy identification of insulation damages.
operating instruction	BA452
article-no. / *colour	9341561xx  00 black  01 red Ni
drawing	
	 Technical drawing showing dimensions (mm): 19, 135, 20, 2, 9.5, 4, 8.8, 4, 66, L. A dashed line indicates the 'Griffbereich handling area'.
technical data	
rated voltage	AC/DC 1000 V
measurement cat. acc. to IEC 61010	CAT II
rated current (consider derating curve)	16 A
material plug	brass, nickel plated
housing material	PA, PP
temperature range acc. To IEC61010 ⁽¹⁾	-15 °C to +70 °C
flammability class acc. to UL 94 (only valid for basic material of housing)	HB
cable length	100 cm
conductor size	1 mm ²

4 mm safety system

cable material	PVC
----------------	-----

⁽¹⁾ contact the manufacturer for applications at deviating temperature ranges
stand: 21.06.2022

stand: 21.06.2022