


Sockets

SEB 2620 F6,3 Ni

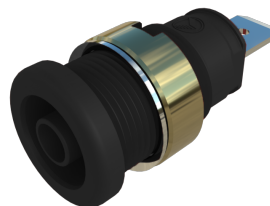

Product	SEB 2620 F6,3 Ni
description	Safety built-in socket, 4 mm diameter, contact-protected, with 6.3 x 0.8 tab connector complying with DIN 46 244, nickel-plated brass. For installation into switchpanels and equipment chassis with wall thicknesses up to 6 mm. Installation hole: 12.2 mm diameter, Tightening torque: 50 Ncm, Accessory: assembly tool MW SEB
operating instruction	BA451
article-no. / *colour	9723562xx ● 00 black ● 01 red ● 02 blue ● 03 yellow ● 04 green Ni
drawing	
technical data	
connection	flat connector 6.3 x 0.8 mm
rated voltage	AC/DC 1000 V
measurement cat. acc. to IEC 61010	CAT III
rated current (consider derating curve)	32 A
material socket	brass, nickel plated
housing material	PA
temperature range acc. To IEC61010 ⁽¹⁾	-40 °C to +80 °C

4 mm safety system

inflammability class acc. to UL 94 (only valid for basic material of housing)	V-2
--	-----

⁽¹⁾ contact the manufacturer for applications at deviating temperature ranges
stand: 09.06.2022

stand: 09.06.2022