
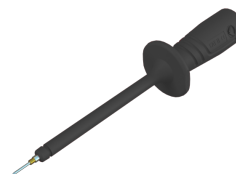


Test probes

PRUEF 2610 FT

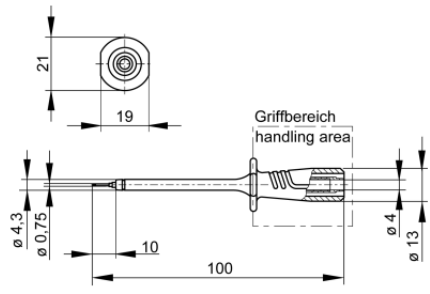

Product	PRUEF 2610 FT
description	Test probe with insulating sleeve and slender, sprung stainless steel tip. This allows a constant pressure to be applied without the tip slipping off the component, even in the smallest measuring points. 4 mm diameter brass socket connection. component part: protector and IC - tap SS 260
operating instruction	BA463
article-no. / *colour	9723181xx  00 black  01 red
drawing	
	
technical data	
connection	unsprung socket 4 mm
rated voltage	AC/DC 1000 V
measurement cat. acc. to IEC 61010	CAT II
rated current (consider derating curve)	1 A
material socket	brass
housing material	PP
temperature range acc. To IEC61010 ⁽¹⁾	-25 °C to +70 °C
flammability class acc. to UL 94 (only valid for basic material of housing)	HB

⁽¹⁾ contact the manufacturer for applications at deviating temperature ranges
 stand: 21.06.2022

stand: 21.06.2022