


Crocodile clips

AK 2 B 2540 I

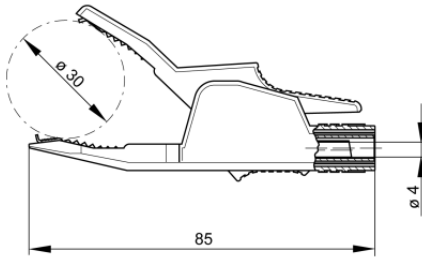

Product	AK 2 B 2540 I
description	Contact-protected, high-strength, wide-opening alligator clip. Clamping range up to 30mm bolt diameter. Solid wire clip, U-shaped and fine wire section. Nickel-plated brass connecting socket, pluggable with 4mm safety measuring leads.
operating instruction	BA465
article-no. / *colour	9724051xx ● 00 black ● 01 red ● 02 blue ● 03 yellow ● 04 green ● 88 yellow green Ni
drawing	
	
technical data	
connection	unsprung socket 4 mm
rated voltage	AC/DC 1000 V
measurement cat. acc. to IEC 61010	CAT II
rated current (consider derating curve)	32 A
material socket	brass, nickel plated
housing material	PP
temperature range acc. To IEC61010 ⁽¹⁾	-30 °C to +70 °C
flammability class acc. to UL 94 (only valid for basic material of housing)	HB

4 mm safety system

clamping range	30 mm
----------------	-------

⁽¹⁾ contact the manufacturer for applications at deviating temperature ranges
stand: 13.02.2023

stand: 13.02.2023