


Measuring leads



MKL 0,64/25-0,25

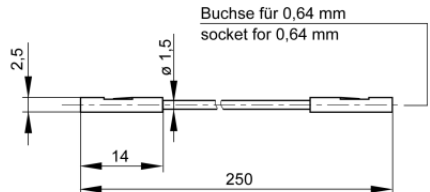

Product	MKL 0,64/25-0,25
description	Measuring lead with two insulated sockets for 0.64 mm round pillar and 0.64 mm rectangular pillar. Highly flexible 0.25 mm ² two stranded wire with two 0.64 mm diameter sockets.
operating instruction	BA001
article-no. / *colour	9736041xx  00 black  01 red Au
drawing	
	 Buchse für 0,64 mm socket for 0,64 mm
technical data	
rated voltage	30 VAC / 60 VDC
measurement cat. acc. to IEC 61010	O ⁽²⁾
rated current (consider derating curve)	3 A
material plug	brass, gold plated
housing material	PPO
temperature range acc. To IEC61010 ⁽¹⁾	-40 °C to +60 °C
flammability class acc. to UL 94 (only valid for basic material of housing)	HB
cable length	25 cm
conductor size	0,25 mm ²
cable material	PVC

0.64 mm system

⁽¹⁾ contact the manufacturer for applications at deviating temperature ranges

⁽²⁾ without rated measurement category, for other circuits that are not directly connected to mains
stand: 21.06.2022

stand: 21.06.2022