


Test probes

PRUEF 2 S

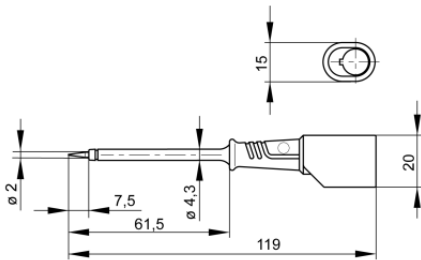

Product	PRUEF 2 S
description	Contact-protected test probe with elastic, shatter-proof insulating sleeve and slender stainless steel tip. Tip penetrates insulation and oxide layers. Insulated brass 4 mm diameter socket connection. Connects with sliding sleeve measuring leads. Accessory tip protector and IC tap SS 260.
operating instruction	BA419
article-no. / *colour	● 00 black ● 01 red
drawing	
technical data	
connection	unsprung socket 4 mm
rated voltage	30 VAC / 60 VDC
measurement cat. acc. to IEC 61010	O ⁽²⁾
material socket	brass
housing material	PP / TPE
temperature range acc. To IEC61010 ⁽¹⁾	-25 °C to +80 °C
flammability class acc. to UL 94 (only valid for basic material of housing)	HB

⁽¹⁾ contact the manufacturer for applications at deviating temperature ranges

⁽²⁾ without rated measurement category, for other circuits that are not directly connected to mains
stand: 21.06.2022

stand: 21.06.2022

4 mm sliding sleeve system