


Clamp-type test probe

KLEPS 1600

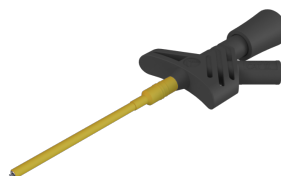

Product	KLEPS 1600
description	Safety clamp-type test probe with rotating grip jaws and flexible shaft. Wires and pins up to a maximum diameter of 3 mm can be clamped thanks to the special form of the grip jaws. Ø 2 mm sockets-connection of brass gold-plated.
operating instruction	BA253
article-no. / *colour	● 00 black ● 01 red Au
drawing	
technical data	
connection	unsprung socket 2 mm
rated voltage	AC/DC 1000 V
measurement cat. acc. to IEC 61010	CAT II
rated current (consider derating curve)	3 A
material socket	brass, gold plated
housing material	PA
temperature range acc. To IEC61010 ⁽¹⁾	-25 °C to +70 °C
flammability class acc. to UL 94 (only valid for basic material of housing)	V-2
clamp type	rotating grip jaws, tin plated

2 mm safety system

clamping range	3 mm
----------------	------

⁽¹⁾ contact the manufacturer for applications at deviating temperature ranges
stand: 21.06.2022

stand: 21.06.2022