



Connectors > RF Coax Connectors > RF Coax Accessories > RF Connector Hardware



RF Connector Hardware Type: Jam Nut

Features

Product Type Features

RF Connector Hardware Type	Jam Nut
----------------------------	---------

Body Features

Body Material	Brass
Body Plating Material	Silver

Operation/Application

For Use With	BNC Connector
--------------	---------------

Packaging Features

Packaging Method	Box & Carton
Packaging Quantity	1000

Product Compliance

[For compliance documentation, visit the product page on TE.com>](#)

EU RoHS Directive 2011/65/EU	Compliant with Exemptions
EU ELV Directive 2000/53/EC	Compliant with Exemptions
China RoHS 2 Directive MIIT Order No 32, 2016	Restricted Materials Above Threshold
EU REACH Regulation (EC) No. 1907/2006	Current ECHA Candidate List: JAN 2021 (211) Candidate List Declared Against: JAN 2021 (211) SVHC > Threshold:



Pb (3.7% in Component Part)

Article Safe Usage Statements:
Do not eat, drink or smoke when using this product. Wash thoroughly after handling. Recycle if possible and dispose of the article by following all applicable governmental regulations relevant to your geographic location.

Halogen Content

Low Halogen - Br, Cl, F, I < 900 ppm per homogenous material. Also BFR/CFR/PVC Free

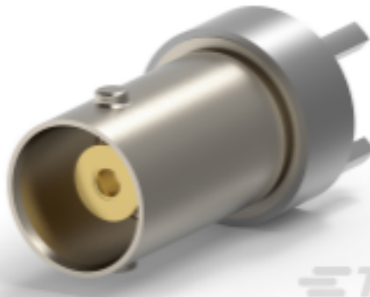
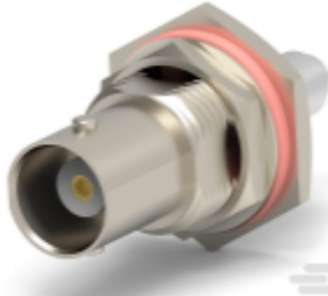
Solder Process Capability

Not applicable for solder process capability

Product Compliance Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) 'Guidance on requirements for substances in articles' posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>

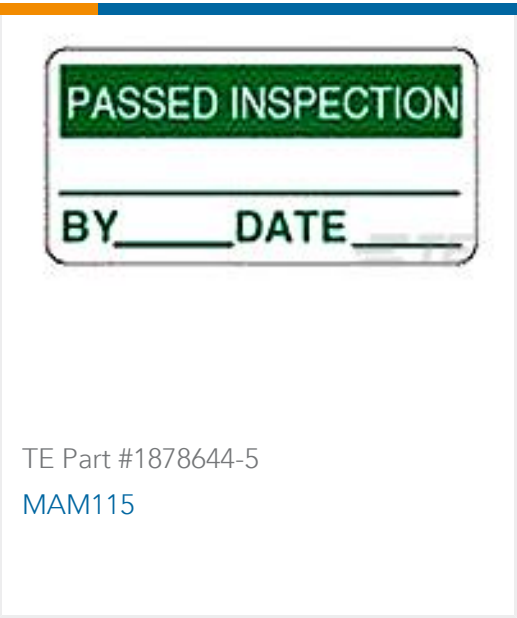
Compatible Parts

 
 TE Part # CAT-076-BNCRABAY BNC Right Angle M Jack RF Connector, 50 Ohm, Bayonet Coupling Mechanism	 TE Part # CAT-076-BNCVTBAY BNC Vertical Male (Jack) RF Connector, 50 Ohm, Bayonet Coupling Mechanism	 TE Part # CAT-076-TNCM50 TNC Connector: Male (Jack), 50 Ohm	 TE Part # 5227426-1 BNC BLKHD RECPT SEALED
 TE Part # 5413771-3 JACK BLKHD,COML BNC,HEX CRIMP	 TE Part # 5225398-7 BNC DUAL CRIMP JACJ	 TE Part # 1-5225398-5 DUAL CRIMP BNC BLKHD JACK	 TE Part # 1-329632-2 LOCKWASHER, PLATED



 TE Part # 1057676-1 3104 7941 00	 TE Part # 1057679-1 3104 7985 00	 TE Part # 227223-1 PANEL INSULATING BUSHING	 TE Part # 5225398-8 BNC JCK DUAL CRMP RG179,187
 TE Part # 5225557-6 TNC-DUAL CMP BKHD JACK-W/P	 TE Part # 5227818-1 TNC PCB RT ANGLE	 TE Part # 5228980-7 JACK,BHD,COML,SERIES BNC,GOLD	 TE Part # 5413771-1 JACK BLKHD,COML BNC,HEX CRIMP
 TE Part # 228502-1 TNC,REAR MOUNTED,JACK ASSY	 TE Part # 2-5329458-1 BNC BHD JACK KIT	 TE Part # CAT-076-BNCJK4GMG BNC RF Connector Jack Kit, 50 Ohm, 4 Ghz, Military Grade	 TE Part # 5227839-1 TNC PCB RT ANGLE JACK

Customers Also Bought

 TE Part #1734260-2 AMP HPI 1.25MM HEADERS	 TE Part #1-329632-2 LOCKWASHER, PLATED	 TE Part #2-1393243-4 RTE25524	 TE Part #9-1879338-4 CPF 0603 249K 1% 50PPM 1K RL
 TE Part #1623375-1 CRG0805 5% 470R	 TE Part #1-5406721-3 MJ,RJ45,SMT,BLACK,22" REEL,30 Au	 TE Part #2-2013298-3 EMBOSS TAPE DDR3 204P 8H RVS Au 0.76	 TE Part #1878644-5 MAM115



Documents

Product Drawings

JAM NUT, PLATED

English

CAD Files

3D PDF

3D

Customer View Model

ENG_CVM_CVM_1-329631-2_AP.2d_dxf.zip

English

Customer View Model

ENG_CVM_CVM_1-329631-2_AP.3d_igs.zip

English

Customer View Model

ENG_CVM_CVM_1-329631-2_AP.3d_stp.zip

English

By downloading the CAD file I accept and agree to the [Terms and Conditions](#) of use.

Datasheets & Catalog Pages

BNC Connectors

English

Product Environmental Compliance

MD_1-329631-2

English

MD_1-329631-2

English