



Application Tooling > Insertion & Extraction Tools



Insertion & Extraction Tool Type: **Contact Extraction**
Insertion & Extraction Tool Application: **Contact-to-Housing**

Features

Product Type Features

Insertion & Extraction Tool Type	Contact Extraction
Insertion & Extraction Tool Application	Contact-to-Housing

Product Compliance

[For compliance documentation, visit the product page on TE.com>](#)

EU RoHS Directive 2011/65/EU	Compliant
EU ELV Directive 2000/53/EC	Out of Scope
China RoHS 2 Directive MIIT Order No 32, 2016	No Restricted Materials Above Threshold
EU REACH Regulation (EC) No. 1907/2006	Current ECHA Candidate List: JAN 2021 (211) Candidate List Declared Against: JAN 2021 (211) Does not contain REACH SVHC
Halogen Content	Low Halogen - Br, Cl, F, I < 900 ppm per homogenous material. Also BFR/CFR/PVC Free
Solder Process Capability	Not applicable for solder process capability

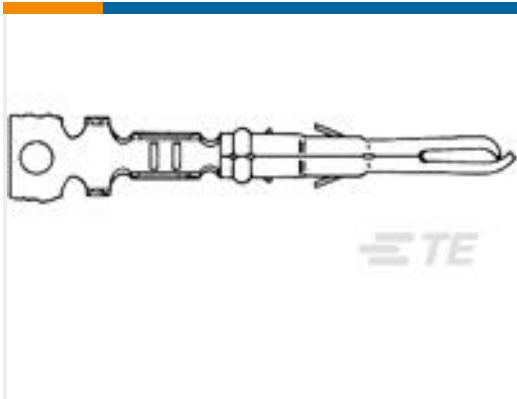
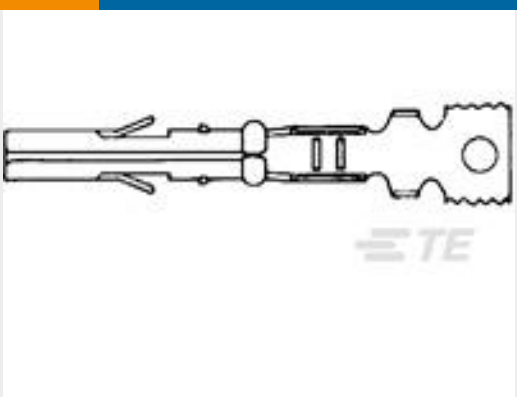
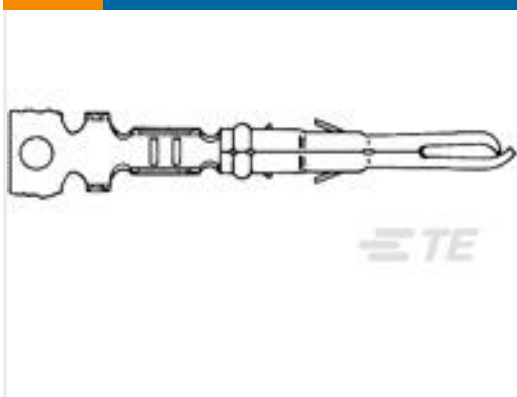
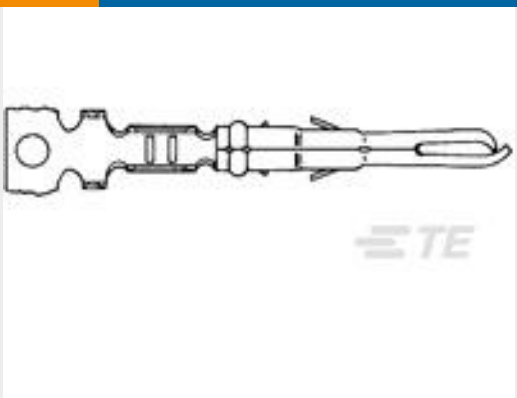
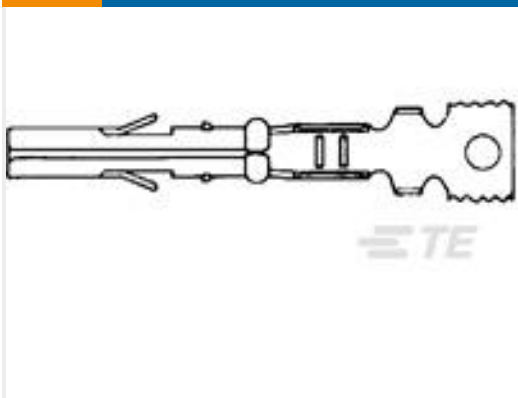
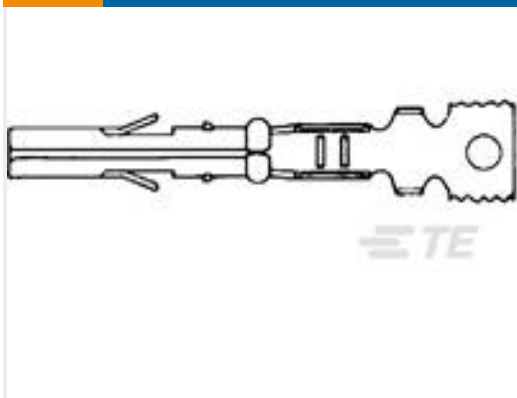
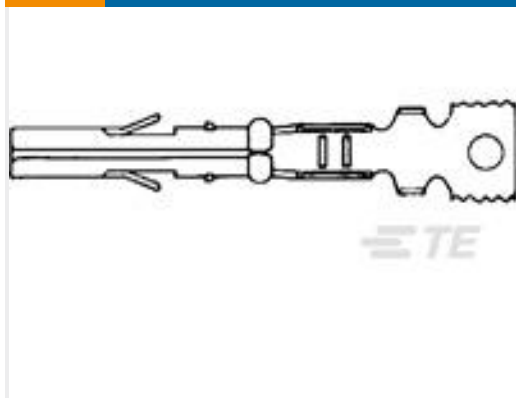
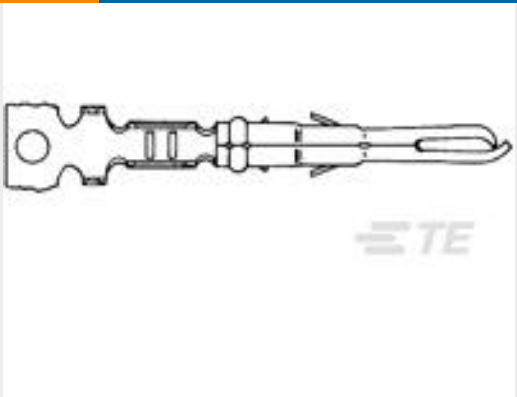
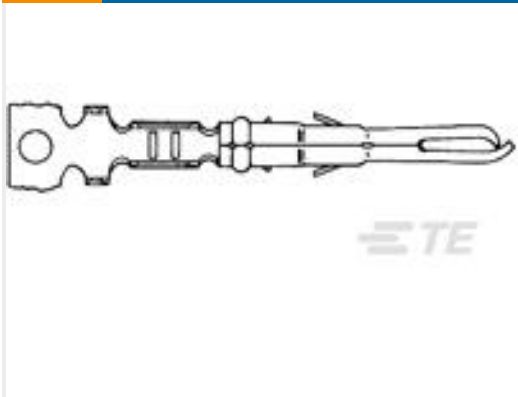
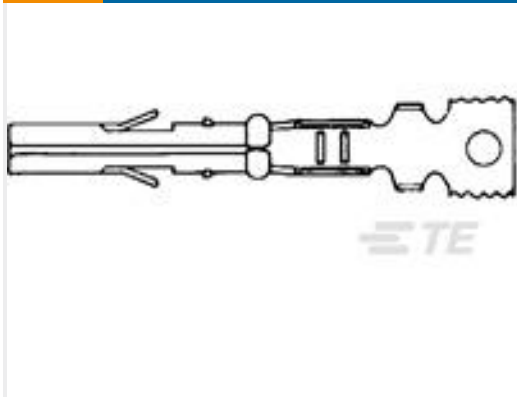
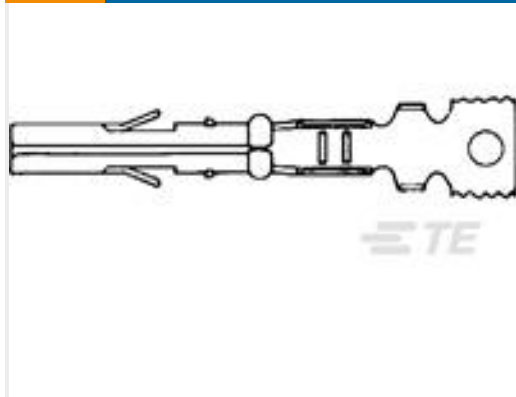
Product Compliance Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides



on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) ‘Guidance on requirements for substances in articles’ posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>

Compatible Parts

 TE Part # 794017-1 .062 CP&S PIN PTPBR L/P 24-18	 TE Part # 350629-5 .062 COMM P&S PIN AUNI/BR	 TE Part # 350967-1 MR PIN PTPPHBZ	 TE Part # 640391-1 .062 COMM P&S PIN 24-30 PTPBR
 TE Part # 641294-1 MR RECPT 26-18 PTPHBZ	 TE Part # 350629-1 .062 COMM P&S PIN 18-24 PTPBR	 TE Part # 350036-1 .058 DIA PIN L/P	 TE Part # 350629-8 .062 COMM P&S PIN PRE TIN/PHBZ
 TE Part # 640545-2 MR SPLIT PIN 26-18 AUPHBRZ LP	 TE Part # 794000-1 MR RECEPTACLE PTPPHBZ	 TE Part # 794001-1 MR RECPT PTPPHBZ LP 26-24	 TE Part # 794001-2 MR RECPT AU PHBZ LP 26-24
 TE Part # 640580-2 MR SPLIT PIN AUPHBRZ LP 26-18	 TE Part # 350968-1 MR PIN 26-24 PTPPHBZ	 TE Part # 350037-1 .058 DIA RECPT L/P	 TE Part # 350019-2 058 REC 26-18 008GPPHBZ



TE Part # 350969-1
MR GRND PIN 26-18 PTPPHBZ

TE Part # 640579-1
MR SPLIT PIN PTPHBRZ LP 26-24

TE Part # 794000-2
MR RECEPTACLE AU PHBZ

TE Part # 640580-1
MR SPLIT PIN PTPHBRZ LP 26-18

Also in the Series

Commercial Pin and Socket Connectors

Connector Contacts(3)

Insertion & Extraction Tools(3)

Power Contacts(39)

Rectangular Connector Housings(11)

Rectangular Power Connectors(88)

Standard Rectangular Connectors(4)

Customers Also Bought

TE Part #205203-8
D-Sub Crimp Recpt Signal 9 Posn,
Socket Size 20, Shell Size 1

TE Part #1804030-1
EXTRACTION TOOL ASSY

TE Part #189727-1
EXTRACTION TOOL

TE Part #1-640518-0
03P MR II PLUG HSG V0 RED

TE Part #1-640517-0
02P MR II PLUG HSG

TE Part #170366-3
MINI UNIVERSAL M-N-L SOCKET LP

TE Part #1052565-1
2052 1618 00

TE Part #1052897-1
2052 5636 00



TE Part #TAA753A5501-002
Fieldbus, DeviceNet M12 A-Code 5p
PUR



TE Part #1-66109-6
III+ SKT,26-24,30AU/FL,SMPACK

Documents

Datasheets & Catalog Pages

[Insertion-Extraction-Tool-2345721-1](#)

English

[Crimp Term Whitepaper-Use the Right Tool 1-1773953-1](#)

English

[CRIMPING WHERE FORM MEETS FUNCTION](#)

English

Instruction Sheets

[Instruction Sheet \(U.S.\)](#)

English