



Connectors > Lighting Connectors > Plug & Socket Connector Accessories



Lighting Connector Accessory Type: Chassis Mount Housing Support

Features

Product Type Features

Product Type	Accessory
Lighting Connector Accessory Type	Chassis Mount Housing Support

Housing Features

Housing Color	White
---------------	-------

Product Compliance

For compliance documentation, visit the product page on TE.com>

EU RoHS Directive 2011/65/EU	Compliant
EU ELV Directive 2000/53/EC	Not Yet Reviewed
China RoHS 2 Directive MIIT Order No 32, 2016	No Restricted Materials Above Threshold
EU REACH Regulation (EC) No. 1907/2006	Current ECHA Candidate List: JAN 2021 (211) Candidate List Declared Against: JAN 2018 (181) SVHC > Threshold: Not Yet Reviewed
Halogen Content	Low Halogen - Br, Cl, F, I < 900 ppm per homogenous material. Also BFR/CFR/PVC Free
Solder Process Capability	Not applicable for solder process capability

Product Compliance Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous




materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulations, TE’s information on SVHC in articles for this part number is still based on the European Chemical Agency (ECHA) ‘Guidance on requirements for substances in articles’(Version: 2, April 2011), applying the 0.1% weight on weight concentration threshold at the finished product level. TE is aware of the European Court of Justice ruling of September 10th, 2015 also known as O5A (Once An Article Always An Article) stating that, in case of ‘complex object’, the threshold for a SVHC must be applied to both the product as a whole and simultaneously to each of the articles forming part of its composition. TE has evaluated this ruling based on the new ECHA “Guidance on requirements for substances in articles” (June 2017, version 4.0) and will be updating its statements accordingly.

### Compatible Parts




TE Part # 293302-1  
NECTOR S CHASSIS MOUNT FRAME


### Customers Also Bought




TE Part #1986715-8  
PWR TB 2PIN 8P,15.00 PCB-FLANGE

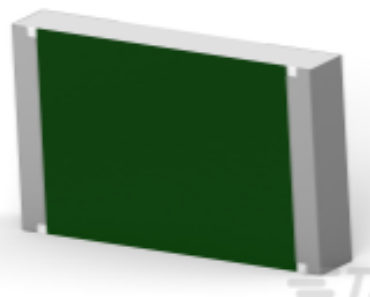


TE Part #2-2176400-0  
3540 6R2 1%

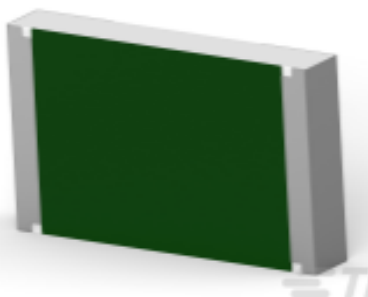


TE Part #2-2176400-4  
3540 9R1 1%




TE Part #2-2213819-7  
6X6 ILL TACT SMT 160GF HI YELLOW GREEN




TE Part #T4171310002-001  
M12 Panel Mount Wire




TE Part #104439-1  
10X2 MTE RCPT SR PLAIN .100CL




TE Part #293315-4  
NECTOR S PCB CONN. ASSY 90 DEG OUTLET



TE Part #293300-1  
NECTOR S BUS BAR ASSY HV-1 TAB WHITE



TE Part #293302-1  
NECTOR S CHASSIS MOUNT FRAME



TE Part #1-293300-1  
NECTOR S BUS BAR ASSY LV-2 TAB YELLOW

### Documents



CAD Files

Customer View Model

ENG\_CVM\_293303-1\_A1.3d\_igs.zip

English

Customer View Model

ENG\_CVM\_293303-1\_A1.3d\_stp.zip

English

Customer View Model

ENG\_CVM\_293303-1\_A1.2d\_dxf.zip

English

3D PDF

English

By downloading the CAD file I accept and agree to the [Terms and Conditions](#) of use.

Datasheets & Catalog Pages

NECTOR\_S\_LINE\_CONNECTOR\_BROCHURE

English

Product Specifications

Product Specification

English