

PRODUCT DATA SHEET

1364u.68

Plug pin – 1364 U Ms sn 7.7x2.4



Product Overview

SKU	1364u.68
Part description	Plug pin
Part designation	1364 U Ms sn 7.7x2.4
Net weight kg/1000	0.058

Material

Component	Brass (CuZn37 CW508L R410)
Surface	tin-plated


Marking

RoHS III, REACH	compliant
-----------------	-----------

Dimension

In addition to the listed tolerances, a barrier layer Ni 0.002 - 0.005 mm and the coating Sn of 0.004 - 0.007 mm are added.

Form	B
ØD [mm]	1.0 +0.04/-0.02
L [mm]	(7.7)
T [mm]	2.4 ±0.2
L1 [mm]	4.8 ±0.2
ØD1 [mm]	2.5 +0/-0.2
B [mm]	1.05 +0.07/-0.03
Hole-Ø [mm]	1.0

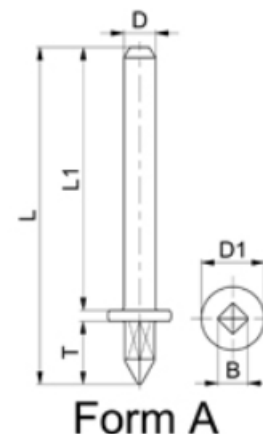

© 2020 / Vogt AG Verbindungstechnik

This leaflet is for general information about the base material only and is not subject to revision.

The data given are no warranty that the product is of a specified quality and they can not replace customer's own test and expert advice regarding the application of the manufactured component.