

PRODUCT DATA SHEET

3509a

Pressed cable terminal uninsulated – Ring shape – 3509 A Cu sn 5-1



Product Overview

SKU	3509a
Part description	Pressed cable terminal uninsulated – Ring shape
Part designation	3509 A Cu sn 5-1

Material

Component	Copper
Surface	pure tin-plated

Technical Details


Net weight kg/1000	0.575
Conductor cross-section	0.5 – 1.5mm ² / AWG 22 – 16
Maximum electrical rating AWG22	9A
Maximum electrical rating AWG20	12A
Maximum electrical rating AWG18	17A
Maximum electrical rating AWG16	18A

Markings

Approved UL	E235797
-------------	---------

Dimensions

for bolt	M5
A [mm]	5.00
D [mm]	5.30
D1 [mm]	1.60
D3 [mm]	8.00
L [mm]	12.50
R [mm]	6.00
S [mm]	0.80

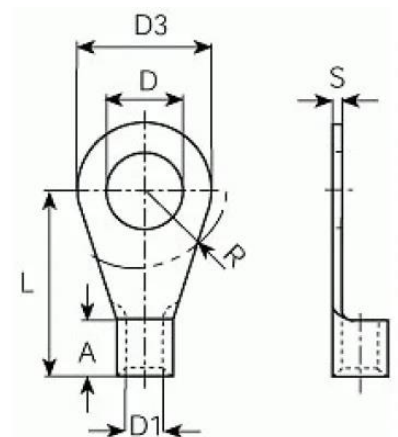

© 2022 | Vogt AG Verbindungstechnik

The general conditions of sale of Vogt AG apply to this product. See www.vogt.ch/downloads.

This data sheet is regularly revised but is not subject to any change service.

This article is a freely available article according to the above specification. The availability of certificates according to EN 10204, others acceptance test certificates or material compliance and customer-specific part submission warrant, are to be requested by the customer and, if available, can be obtained for a fee.

You can find more information on the free available product conformities at www.vogt.ch/downloads.

Form checked and approved special field: 17.02.2022 haatob
Form created: 17.02.2022 haatob

PDS_3509a_EN_V1.docx
Content created: 19.04.24 karlea / Version: 01

Page 1 / 1
PM-FO-03 / Version: 00

Vogt AG Verbindungstechnik
+41 62 285 75 75

Duschletenstrasse 2 – 4
info@vogt.ch

4654 Lostorf / Switzerland
www.vogt.ch