

PRODUCT DATA SHEET

3607a

Pressed cable terminal insulated – Ring shape – 3607 A Cu sn PVC rot 4-1



(Image may differ)

Product Overview

SKU	3607a
Part description	Pressed cable terminal insulated – Ring shape
Part designation	3607 A Cu sn PVC rot 4-1

Material

Component	Copper
Surface	pure tin-plated
Insulationsmaterial / Color	PVC / red

Technical Details


Net weight kg/1000	0.666
Conductor cross-section	0.5 - 1.5mm ² / AWG 20 – 16
Temperature resistance	bis 105°C (600V max.)
Maximum electrical rating AWG22	9A
Maximum electrical rating AWG20	12A
Maximum electrical rating AWG18	17A
Maximum electrical rating AWG16	18A

Markings

Approved UL	E235797
UL Standard / Flammability class	UL94 / V-0

Dimensions

for bolt	M4
A [mm]	5.00
D [mm]	4.30
D1 [mm]	1.60
D3 [mm]	7.00
D4 [mm]	4.00
L [mm]	16.50
R [mm]	5.50
S [mm]	0.80

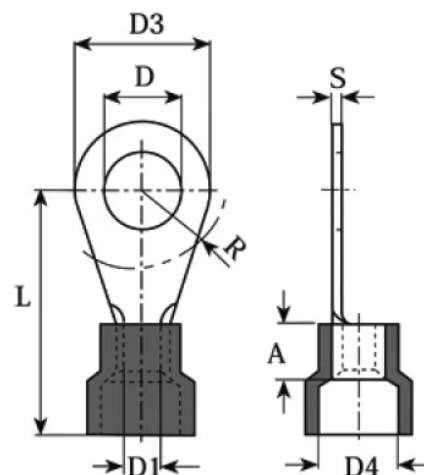

© 2022 | Vogt AG Verbindungstechnik

The general conditions of sale of Vogt AG apply to this product. See www.vogt.ch/downloads.

This data sheet is regularly revised but is not subject to any change service.

This article is a freely available article according to the above specification. The availability of certificates according to EN 10204, others acceptance test certificates or material compliance and customer-specific part submission warrant, are to be requested by the customer and, if available, can be obtained for a fee.

You can find more information on the free available product conformities at www.vogt.ch/downloads.

Form checked and approved special field: 17.02.2022 haatob
Form created: 17.02.2022 haatob

PDS_3607a_EN_V1.docx
Content created: 19.04.24 karlea / Version: 01

Page 1 / 1
PM-FO-03 / Version: 00

Vogt AG Verbindungstechnik
+41 62 285 75 75

Duschletenstrasse 2 – 4
info@vogt.ch

4654 Lostorf / Switzerland
www.vogt.ch