

PRODUCT DATA SHEET

3628c

Pressed cable terminal insulated - Spade shape – 3628 C Cu sn PVCblau4-2.5



(Image may differ)

Product Overview

SKU	3628c
Part description	Pressed cable terminal insulated – Spade shape
Part designation	3628 C Cu sn PVCblau4-2.5

Material

Component	Copper
Surface	pure tin-plated
Insulationsmaterial / Color	PVC / blue

Technical Details


Net weight kg/1000	0.778
Conductor cross-section	1.5 – 2.5mm ² / AWG 16 – 14
Temperature resistance	bis 105°C (600V max.)
Maximum electrical rating AWG16	18A
Maximum electrical rating AWG14	30A

Markings

Approved UL	E235797
UL Standard / Flammability class	UL94 / V-0

Dimensions

for bolt	M4
A [mm]	5.00
D [mm]	4.30
D1 [mm]	2.30
D3 [mm]	6.80
D4 [mm]	4.50
L [mm]	17.70
R [mm]	4.50
S [mm]	0.80

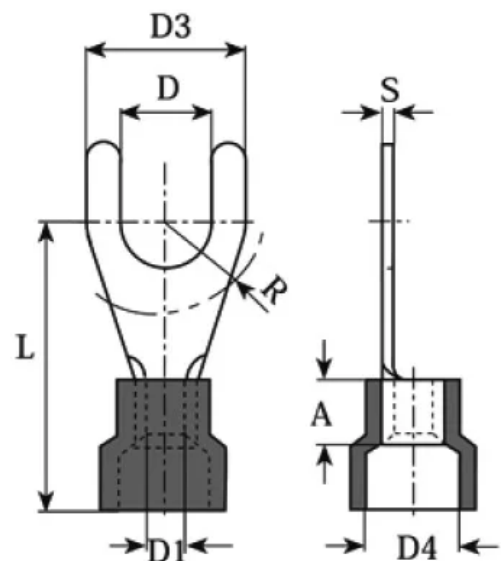

© 2022 | Vogt AG Verbindungstechnik

The general conditions of sale of Vogt AG apply to this product. See www.vogt.ch/downloads.

This data sheet is regularly revised but is not subject to any change service.

This article is a freely available article according to the above specification. The availability of certificates according to EN 10204, others acceptance test certificates or material compliance and customer-specific part submission warrant, are to be requested by the customer and, if available, can be obtained for a fee.

You can find more information on the free available product conformities at www.vogt.ch/downloads.

Form checked and approved special field: 17.02.2022 haatob

Form created: 17.02.2022 haatob

PDS_3628c_EN_V1.docx

Content created: 19.04.24 karlea / Version: 01

Page 1 / 1

PM-FO-03 / Version: 00