

# PRODUCT DATA SHEET

**3833.61**

**Receptacles – 3833 Ms ag 6.3x0.8/2.5**



## Product Overview

<b>SKU</b>	<b>3833.61</b>
<b>Part description</b>	<b>Receptacles</b>
<b>Part designation</b>	<b>3833 Ms ag 6.3x0.8/2.5</b>

### Material

Component	Brass
Surface	Silver-plated

### Technical Details

Net weight kg/1000	0.740
Conductor cross-section	1.0 – 2.5mm <sup>2</sup> / AWG 18-14
Max. Temp. [C°]	-
Contact Resist [mΩ]	-

### Max. rated current


Wire section 1.00 mm <sup>2</sup>	12A
Wire section 1.50 mm <sup>2</sup>	16A
Wire section 2.50 mm <sup>2</sup>	20A

### Marking

RoHS, REACH, CRMT	compliant
DIN	46247/T3

### Dimensions

Size	6.3x0.8
L1 [mm]	19
L2 [mm]	7.7
L3 [mm]	4
A1 [mm]	8.5
A2 [mm]	4
S [mm]	0.4

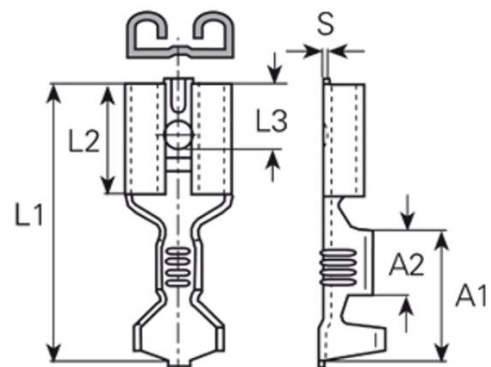

© 2020 / Vogt AG Verbindungstechnik

This leaflet is for general information about the base material only and is not subject to revision.

The data given are no warranty that the product is of a specified quality and they cannot replace customer's own test and release regarding the application of the manufactured component.