


Technical data and line drawing

尺寸及形状(单体)/Measurement & Dimensions(cell)

如图所示/ to see the drawing:


D	25.0~25.5mm
H	48.5~50.0mm
D1	$7.5 \pm 0.2\text{mm}$
H1	$2.2 \pm 0.3\text{mm}$

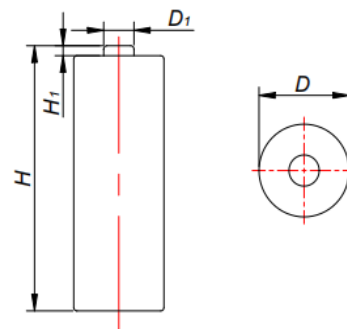

Type designation:	
Chemical system:	Ni-MH battery
Nominal voltage:	1.2V
Weight:	90 g
Dimension:	in mm
Capacity:	5500 mAh
Operating temperature:	-20 °C ~ 55 °C
Recommended temperature:	-20°C ~ 55°C
Recommend storage temperature:	-20~35°C
Shelf lifetime:	2 Years

The dimensions shall be in accordance with the above figures both prior to and after the service output test.
Measuring equipment shall be with a minimum accuracy of $\pm 0.05\text{mm}$.

Performance Characteristics (20°C)

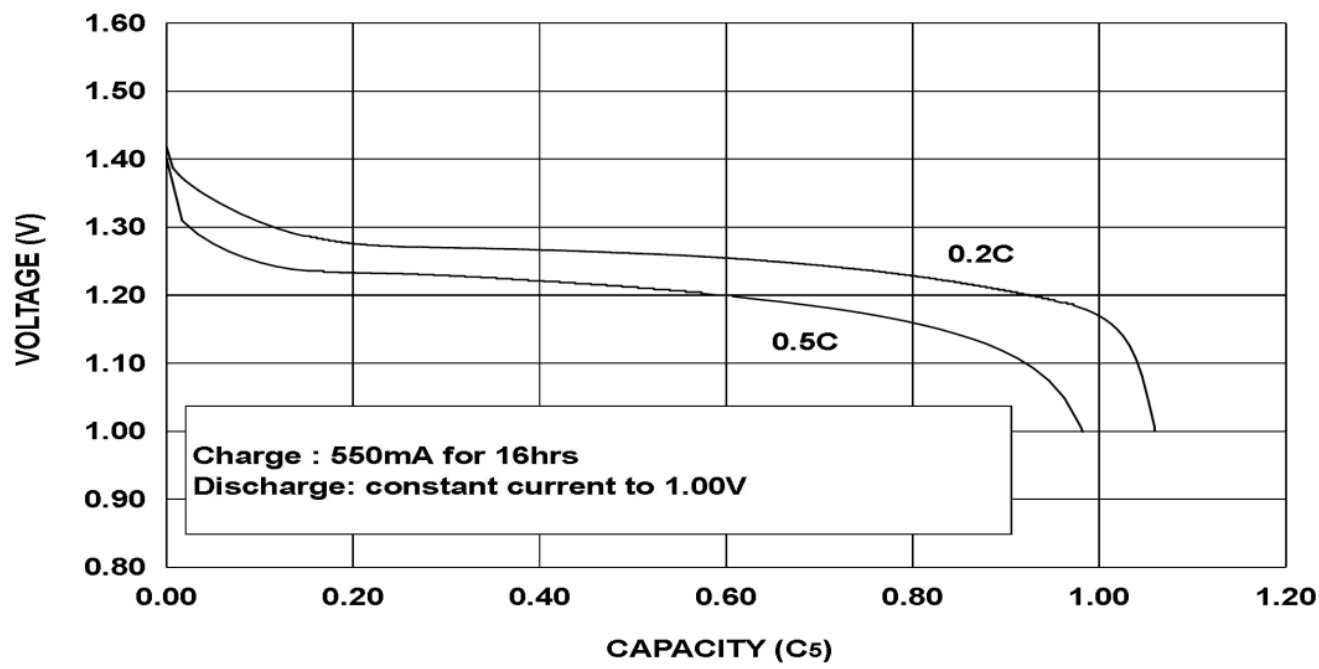

Revision Date: 21/06/2024