

DATASHEET

Item No.: 2542824

Type designation: ER34615 Size: D

Chemical system: Li/SOCl₂


Nominal voltage: 3.6 V

Max weight: 109g

Max dimension: 34.2mm × 61.5mm

Measuring equipment shall be with a minimum accuracy of ±0.05mm

Cell Dimension: mm

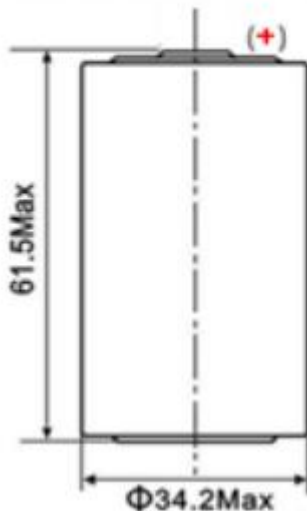

Nominal Capacity: 19000 mAh

Operating temperature: -55 °C ~ +50 °C

Recommended temperature: +10°C ~ +25°C

Recommend storage temperature: ≤30°C

Shelf lifetime: ≥10 Years