

DATASHEET

Item No.: 2898205

Type designation: HR6 Common: AA

Chemical system: LITHIUM-ION


Nominal voltage: 1.5 V

Weight: Approximate 17.5 ± 0.5 g

Dimension (mm)

The dimensions shall be in accordance with the below figures both prior to and after the service output test.

Measuring equipment shall be with a minimum accuracy of ± 0.05 mm.

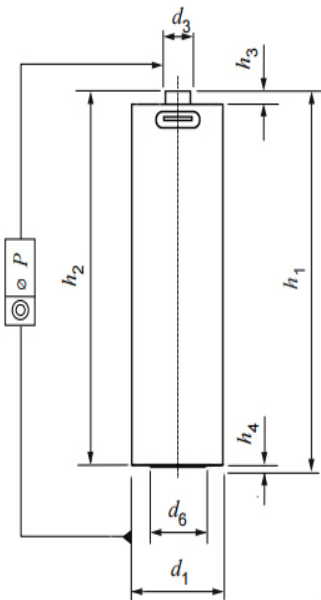

Diameter (d1)	Min 13.7mm, Max 14.5mm
Height (h1)	Min 49.5mm, Max 50.5mm

Capacity: 1300 mAh (130 mA, 25°C, e.v.= 1.1 V)

Operating temperature: Charge 0 °C ~ 45 °C

Discharge -10 °C ~ 55 °C

Recommend storage temperature: -5 -- 30°C

Shelf lifetime: 1 Year