

DATASHEET

Item No.: 2898206

Type designation: HR03 Common: AAA

Chemical system: LITHIUM-ION


Nominal voltage: 1.5 V

Weight: Approximate 7.2 ± 0.3 g

Dimension (mm)

The dimensions shall be in accordance with the below figures both prior to and after the service output test.

Measuring equipment shall be with a minimum accuracy of ± 0.05 mm.

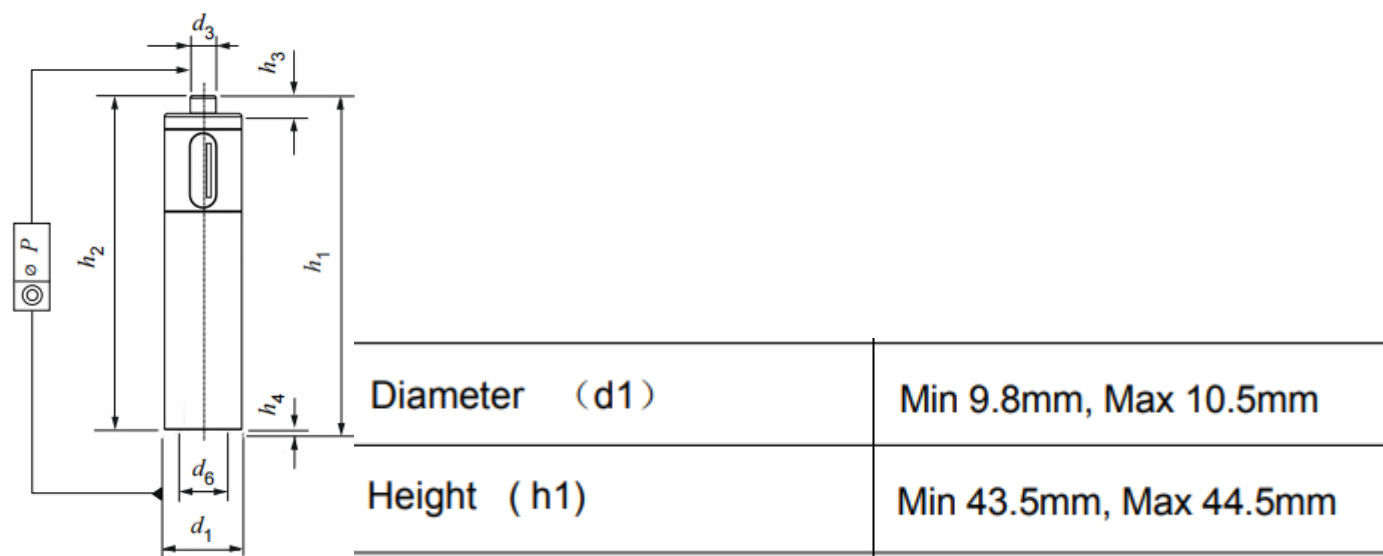

Capacity: 400 mAh (100 mA, 25°C, e.v.= 1.1 V)

Operating temperature: Charge 0 °C ~ 45 °C

Discharge -10 °C ~ 55 °C

Recommend storage temperature: 5--30°C

Shelf lifetime: 1 Year