

## DATASHEET

Item No.: 2973095

Type designation: HR6 Common: AA

Chemical system: Ni-MH

Nominal voltage: 1.2 V

Weight: Approximate 25.5 g

Dimension (mm)


The dimensions shall be in accordance with the below figures both prior to and after the service output test.

Measuring equipment shall be with a minimum accuracy of  $\pm 0.05\text{mm}$ .

尺寸及形状(单体)/Measurement & Dimensions(cell)

如图所示/ to see the drawing:

|    |                        |
|----|------------------------|
| D  | 13.8-14.5mm            |
| H  | 49.0-50.5mm            |
| D1 | $5.4 \pm 0.2\text{mm}$ |
| H1 | $1.5 \pm 0.3\text{mm}$ |

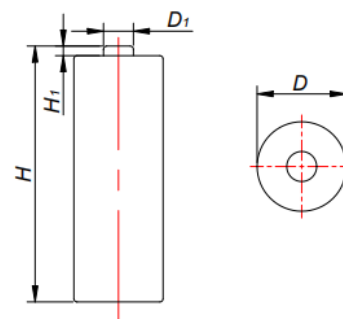

Capacity: 1800 mAh (18 mA, 24 h/d, 20°C, e.v.= 1.0 V)

Operating temperature: -40 °C ~ 55 °C

Recommend storage temperature:  $20 \pm 2^\circ\text{C}$

Shelf lifetime: 5 Years