






Technical data and line drawing

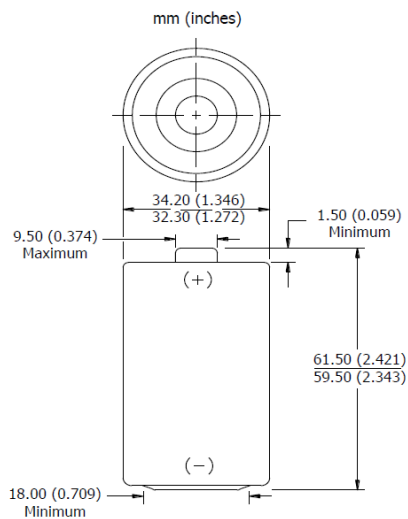

Type designation:	LR20 (Common:D)
Chemical system:	Alkaline
Nominal voltage:	1.5 V
Weight:	142.3 g
Dimension:	in mm
Capacity:	18000 mAh
Operating temperature:	-18 °C ~ 50 °C
Recommended temperature:	10°C ~ 25°C
Recommend storage temperature:	21°C
Shelf lifetime:	7 Years

The dimensions shall be in accordance with the above figures both prior to and after the service output test.
Measuring equipment shall be with a minimum accuracy of $\pm 0.05\text{mm}$.

Performance Characteristics (21°C)

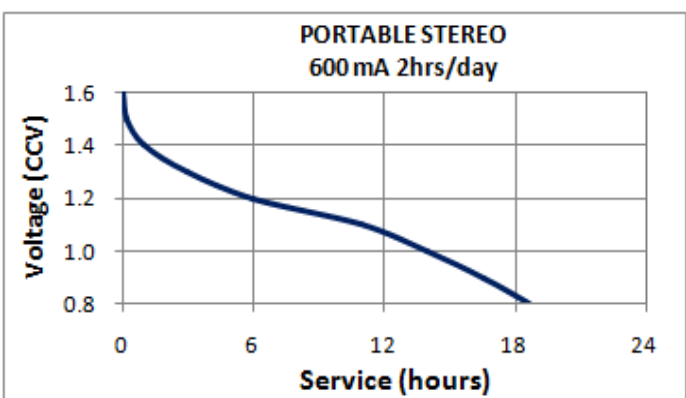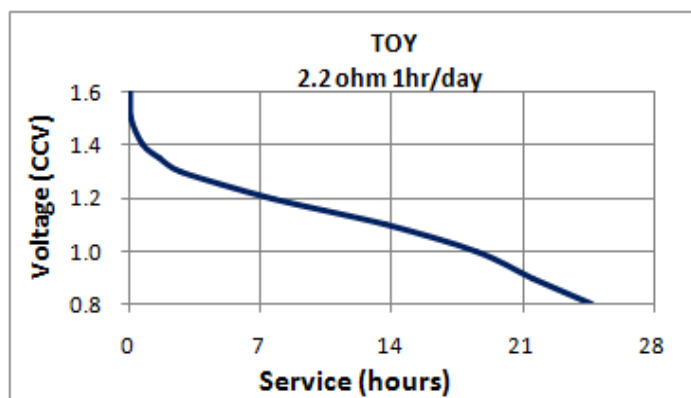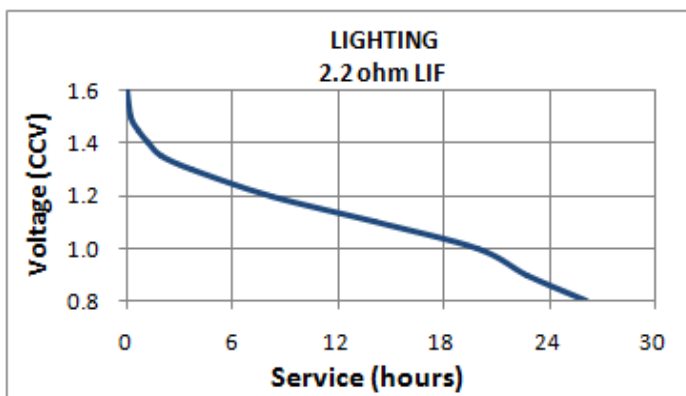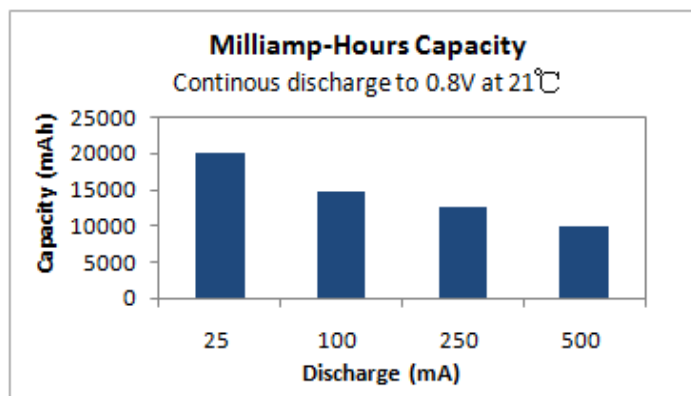

Revision Date: 22/07/2024