




2520⁰⁰⁰

wolcraft®

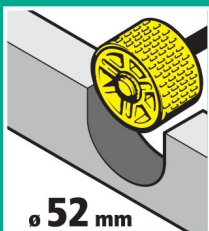


Ø 52 mm

↑
30
mm
↓



wolcraft GmbH
Wolffstraße 1
56746 Kempenich
Germany
www.wolcraft.com

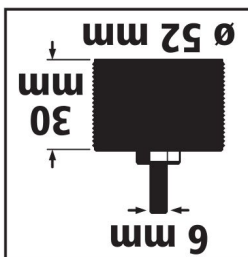

max.
3.000
RPM

WS

2520⁰⁰⁰

140002520 - V40