

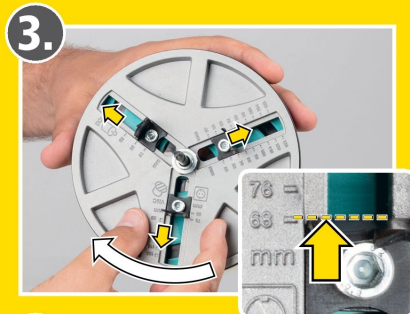
 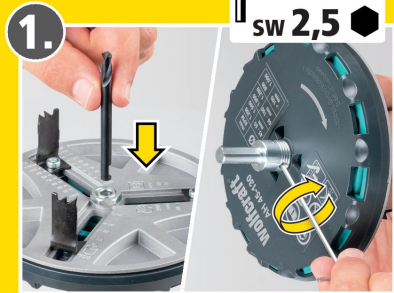


AH 45-130


wolcraft®

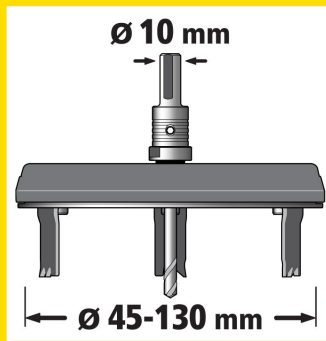

Ø mm	max. RPM
45 - 65 mm	1.200 1.500
66 - 100 mm	1.000 1.200
> 100 mm	800 1.000



wolcraft GmbH
Wolffstraße 1
56746 Kempenich
Germany
www.wolcraft.com

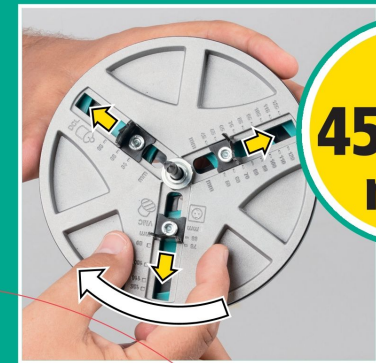

Ø
**45-130
mm**

