


UL2651 6 Way Grey Ribbon
Cable 18-3728

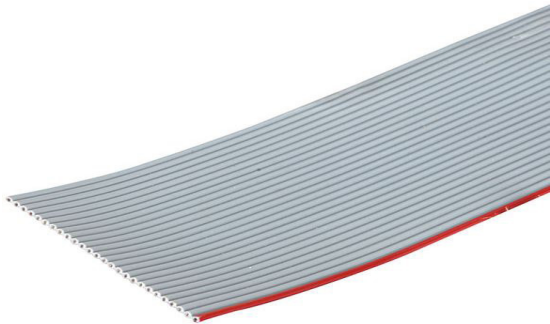

Part Number	UNIRIB6WG
Description	UL2651 Ribbon Cable
Conductor Size	28AWG or 30AWG
Insulation	PVC
Colour	Grey
Diameter	0.100 (30AWG) 0.127 (28AWG)
Insulation Resistance	100 Ω /km
Flammability Rating	VW-1
Voltage Rating	300V
Edge Mark	Red
Temperature Range	-20°C to 105°C
Length Supplied	30m +/- 10-12%

* Figure is nominal, exact number of strands used may be lower

