


PRODUCT DATA SHEET

LR14 ALKALINE POWER



Ref.no. AL-PO-LR14-V23-09

Date of issue: 1 October, 2023

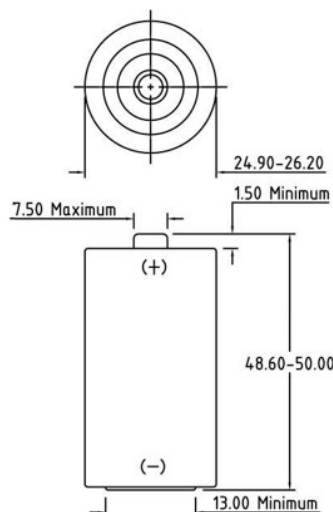

Type Designation	IEC: LR14 / JIS: AM2 / ANSI: 14A /C
Made in	China
Chemical System	Electrolyte-zinc-manganese dioxide (mercury & cadmium free)
Dimensions	Diameter: 24.0–26.2mm Height: 48.6–50 mm
Nominal Voltage	1.5 V
Average Weight	66.5 g
Compliant to	IEC 60086-1, IEC 60086-2, IEC 60086-5, non-dangerous goods regulation EU directive 2006/66/EC
Heavy metals	No added mercury (Hg), Cadmium (Cd) or Lead (Pb)
Storage Temp. Range	+10°C (50°F)- +25°C (77°F)
Operating temp Range	-20°C (-4°F)- +55°C (131°F)

Appearance and terminal

Battery shall be clean and have no dirt, no leakage, and no deformation which may affect their performance and actual use and shall have clearly visible markings.

Expiry period marking

Expiry date marked on the bottom of the finished battery. (for example: "2027-08" means the expiry date is August 2027)

Discharge curve

