


PR312 ZINC AIR



Ref.no. ZC-AIR-PR312-V23-09

Date of issue: 1 October, 2023

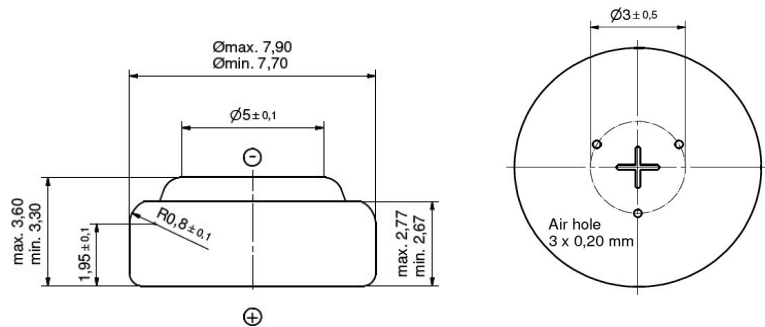

Type Designation	IEC: PR312
Made in	Germany
Chemical System	Zinc oxygen
Dimensions	Diameter: 7.7–7.9 mm Height: 3.3-3.6mm
Nominal Voltage	1.45 V
Average Weight	0.58 g
Compliant to	IEC 60086-1, IEC 60086-2, IEC 60086-5, non-dangerous goods regulation EU directive 2006/66/EC
Heavy metals	No added mercury (Hg), Cadmium (Cd) or Lead (Pb)
Storage Temp. Range	+10°C (50°F)- +25°C (77°F)
Operating temp Range	-20°C (-4°F)- +55°C (131°F)

Appearance and terminal

Battery shall be clean and have no dirt, no leakage, and no deformation which may affect their performance and actual use and shall have clearly visible markings.

Discharge curve (at 20°C / 55% r.h)

